


# ProLine Sloped-Front HMI Enclosure Rear Door

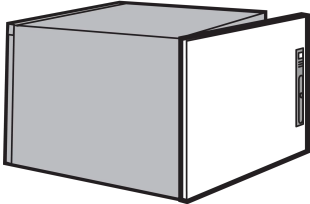

Rear doors are side-hinged. The hinges are hidden and provide 130-degree door swing. Optional ProLine 180-Degree Hinge Kit is available. Doors can be hinged from left or right. Door includes two-point latching with a flush slotted quarter-turn insert. Standard ProLine handle and insert options are available for retrofit. Use ProLine Frame Shelf or ProLine Grid Straps to support the operator interface. Ground stud and mounting hardware are included. Seamless foam-in-place gasket assures a watertight and dust-tight seal.

## FEATURES

---

Side hinged doors with 130-degree swing

Seamless foam in place gasket

## SPECIFICATIONS

**Color:** Light Gray  
**Material:** Mild Steel  
**Finish:** Powder Coated  
**Color Code:** RAL 7035

Table 1/1

Catalog Number	Article Number	Height	Width	Depth	Thickness	Door Size
PDS46R	36849	15.75in	23.62in	22.23in	16ga	15.96 x 23.30in
PDS56R	36859	19.69in	23.62in	22.23in	16ga	19.91 x 23.30in
PDS5A6R	36869	19.69in	23.62in	22.23in	16ga	26.75 x 23.30in
PDS5A8R	36879	19.69in	31.5in	22.23in	16ga	26.75 x 31.17in
PDS76STR	38159	27.56in	23.62in	22.23in	16ga	27.79 x 23.30in
PDS78STR	38169	27.56in	31.5in	22.23in	16ga	27.79 x 31.17in
PDS7A6R	36889	27.56in	23.62in	22.23in	16ga	34.62 x 23.30in
PDS7A8R	36899	27.56in	31.5in	22.23in	16ga	34.62 x 31.17in

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**