


Rack Mounting Angle L Style for 24-in. wide Wall-Mount

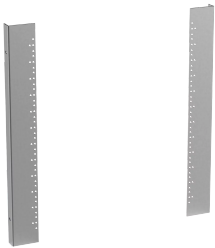

Rack mounting angles are designed for standard 24-in. (610-mm) wide one-door, Wall-Mount Type 4 and 12 enclosures. A pair of pre-cut rack mounting angles are available for mounting 19-in. (483-mm) rack-mounted equipment. To install, drill small holes in the sides of the enclosure and bolt angles in place.

FEATURES

Rack mounting angles have mounting holes tapped #10-32 thread and spaced per EIA 310-D standard

All mounting hardware and instructions are furnished

Stainless steel external screws and sealing washers are provided to maintain original enclosure standards rating after installation

SPECIFICATIONS

Table 1/1						
Catalog Number	Article Number	Material	Finish	Thickness	Fits Enclosure Size	Unit Quantity
ARAK36	21680	Mild Steel	Zinc Plated	10ga	36.00 x 24.00in	19
ARAK24	21660	Mild Steel	Zinc Plated	10ga	24.00 x 24.00in	12
ARAK30	21670	Mild Steel	Zinc Plated	10ga	30.00 x 24.00in	15

ADDITIONAL PRODUCT DETAILS

One unit equals 1.75-in (44-mm).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE