


Sealing Plate 90-Degree Angle Lay-in Hinged-Cover

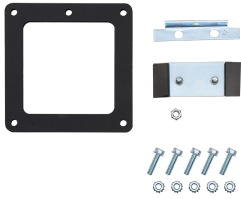

Lay-in Hinged-Cover 90-Degree Angle Sealing Plates are used for junction to a lay-in wireway section or fitting to a closure plate, a box connector, a non-lay-in cut-off fitting or any similar non-lay-in section or fitting. Each sealing plate also includes one gasket and one set of screws to join sections.

FEATURES

Lay-in Hinged-Cover 90-Degree Angle Sealing Plates are used for junction to a lay-in wireway section or fitting to a closure plate, a box connector, a non-lay-in cut-off fitting or any similar non-lay-in section or fitting

Each sealing plate also includes one gasket and one set of screws to join sections

SPECIFICATIONS

Color Code: ANSI 61
Finish: Galvanized; Powder Coated
Color: Gray
Material: Mild Steel

Table 1/1						
Catalog Number	Article Number	Type	Height	Width	Thickness	Quick Ship
F22LSAG	18230	Sealing Plate	2.5in	2.5in	14ga	No
F44LSAG	18470	Sealing Plate	4in	4in	14ga	No
F66LSAG	18710	Sealing Plate	6in	6in	14ga	No
F88LSAG	19400	Sealing Plate	8in	8in	14ga	No
F126LSAG	18920	Sealing Plate	12in	6in	14ga	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE