


Split Bottom Plates Stainless Steel, CBPS

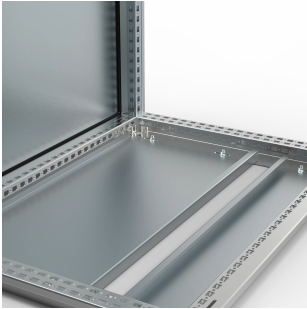

A split bottom plate offers a flexible cabling solution and eliminates the need for individual cable glands. The protection degree is maintained by using a separate gasket.

FEATURES

Description: Fitted in place of the standard one piece bottom plate, allows direct cable entry. To achieve perfect sealing around the cables use the gasket kit BG01.

Material: AISI 304 / AISI 316L pre-grained stainless steel.

Bottom plates: 1.5 mm.

Finish: 400 pre-grained stainless steel.

Pack quantity: 1 kit of two part bottom plate.

SPECIFICATIONS

Thickness: 0.06in

Finish: Brushed

Table 1/1

Catalog Number	Height	Width	Depth	Enclosure Material	Material	Quick Ship
CBPS0640	0.98in	23.62in	15.75in	Stainless Steel	Stainless Steel 304	No
CBPS0640-316	0.98in	23.62in	15.75in	Stainless Steel	Stainless Steel 316	No
CBPS0650	0.98in	23.62in	19.69in	Stainless Steel	Stainless Steel 304	No
CBPS0650-316	0.98in	23.62in	19.69in	Stainless Steel	Stainless Steel 316	No
CBPS0660	0.98in	23.62in	23.62in	Stainless Steel	Stainless Steel 304	No
CBPS0660-316	0.98in	23.62in	23.62in	Stainless Steel	Stainless Steel 316	No
CBPS0840	0.98in	31.5in	15.75in	Stainless Steel	Stainless Steel 304	No
CBPS0840-316	0.98in	31.5in	15.75in	Stainless Steel	Stainless Steel 316	No
CBPS0850	0.98in	31.5in	19.69in	Stainless Steel	Stainless Steel 304	No
CBPS0850-316	0.98in	31.5in	19.69in	Stainless Steel	Stainless Steel 316	No
CBPS0860	0.98in	31.5in	23.62in	Stainless Steel	Stainless Steel 304	No
CBPS0860-316	0.98in	31.5in	23.62in	Stainless Steel	Stainless Steel 316	No
CBPS1040	0.98in	39.37in	15.75in	Stainless Steel	Stainless Steel 304	No
CBPS1040-316	0.98in	39.37in	15.75in	Stainless Steel	Stainless Steel 316	No
CBPS1050	0.98in	39.37in	19.69in	Stainless Steel	Stainless Steel 304	No
CBPS1050-316	0.98in	39.37in	19.69in	Stainless Steel	Stainless Steel 316	No
CBPS1060	0.98in	39.37in	23.62in	Stainless Steel	Stainless Steel 304	No

Catalog Number	Height	Width	Depth	EnclosureMaterial	Material	Quick Ship
CBPS1060-316	0.98in	39.37in	23.62in	Stainless Steel	Stainless Steel 316	No

ADDITIONAL PRODUCT DETAILS

For enclosures 1200 mm & 1600 mm wide use 2 x 600 mm & 2 x 800 mm wide bottom plates.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE