


# TFP Exhaust Grilles

Type 1 or Type 12 exhaust option for TFP Filter Fans

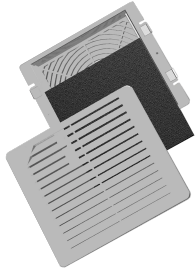

## FEATURES

---

TFP Exhaust Grilles includes standard replacement filters that are washable foam (Type 1) or disposable (Type 12)

To maintain UL Type 12 rating on the enclosure, UL Type 12 filters must be used on the fan package inlet

## SPECIFICATIONS

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Material	Finish
TEP4	12774	6.25in	7.33in	1.38in	Composite	Smooth Matte
TEP4UL12	12777	6.25in	7.33in	1.38in	Composite	Smooth Matte
TEP6	12775	7.77in	8.83in	1.25in	Composite	Smooth Matte
TEP6UL12	12778	7.77in	8.83in	1.25in	Composite	Smooth Matte
TEP4SS	11228	6.25in	7.33in	1.38in	Stainless Steel 304	Brushed
TEP6SS	11231	7.77in	8.83in	1.25in	Stainless Steel 304	Brushed
TEP10	12776	11.77in	12.94in	1.32in	Composite	Smooth Matte
TEP10UL12	12781	11.77in	12.94in	1.32in	Composite	Smooth Matte
TEP10SS	11232	11.77in	12.94in	1.32in	Stainless Steel 304	Brushed

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**