


Ultrix Swing Frame

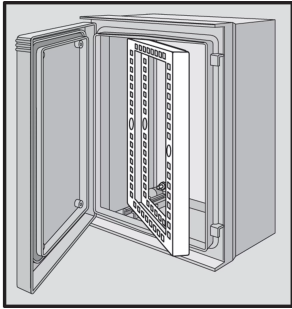

Swing Frame provides 19-inch rack-mounting capabilities with U-Style (Type RA) mounting hole pattern. Quarter-turn latch has 100-degree swing. Adjustable mounting provision. Swing frame maintains enclosure rating if properly installed in an nVent HOFFMAN enclosure. Front mounting position is approximately 140mm (5.5 inch) back on 400mm enclosures. Includes mounting hardware and instruction manual.

CERTIFICATIONS



FEATURES

For use with Ultrix Series Products

SPECIFICATIONS

Table 1/1						
Catalog Number	Article Number	Material	Finish	Thickness	Rack Units	Quick Ship
UU6060SF	61490	Mild Steel	Zinc Plated	14ga	11U	No
UU7560SF	61500	Mild Steel	Zinc Plated	14ga	14U	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE