

CIPP Tapered Plastic Push-In Plug for A12



FEATURES

Designed for use with the A12 coupler families

Designed to keep dirt and water out of the coupler during transportation and installation

Color coded for the appropriate coupler size

SPECIFICATIONS


Material: Polyethylene

Table 1/1

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL10CIPP	#3		0.59"	0.28"	Yellow
EL12CIPP	#4	10M	0.67"	0.28"	Red
EL14CIPP			0.76"	0.28"	Green
EL16CIPP	#5	15M	0.84"	0.28"	Black
EL18CIPP			0.95"	0.28"	White
EL20CIPP	#6	20M	1.06"	0.34"	Yellow

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL22CIPP	#7		1.15"	0.34"	Blue
EL25CIPP	#8	25M	1.27"	0.34"	Red
EL28CIPP	#9	30M	1.39"	0.34"	Black
EL30CIPP			1.48"	0.34"	White
EL32CIPP	#10		1.56"	0.38"	Yellow
EL34CIPP			1.65"	0.38"	Red
EL36CIPP	#11	35M	1.73"	0.38"	Blue
EL38CIPP	#12		1.81"	0.38"	White
EL40CIPP			1.89"	0.38"	Green
EL43TCIPP	#14	45M	2.13"	0.44"	Red
EL50TCIPP			2.42"	0.44"	Black
EL57TCIPP	#18	55M	2.71"	0.44"	Blue

DIAGRAMS

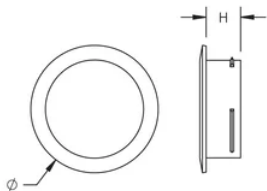

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE