

PPP Parallel Plastic Screw-In Plug for P13/P14, Worldwide Design



FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

SPECIFICATIONS


Design Version: Worldwide (Globally Available Materials)

Table 1/1

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL12PPPNB100	#4	10M	0.98"	0.51"	Red
EL16PPPNB100	#5	15M	1.18"	0.51"	Black
EL28PPPNB50	#9	30M	1.97"	0.63"	Black
EL20PPPNB100	#6	20M	1.38"	0.63"	Yellow
EL32PPPNB50	#10		2.36"	0.63"	Yellow

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)	Color
EL25PPPNB100	#8	25M	1.77"	0.63"	Red
EL22PPPNB100	#7		1.57"	0.63"	Blue
EL40PPPNB25			2.76"	0.63"	Green
EL36PPPNB25	#11	35M	2.56"	0.63"	Blue

DIAGRAMS

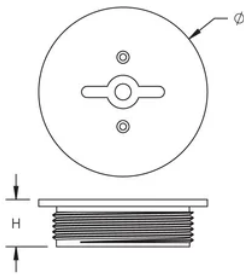

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE