


AC11 Option

The AC11 option is the internal audible alarm option that contains an 80 dB, 4 kHz continuous siren, a red trouble LED, and one green LED per phase. These circuits are optimized to minimize power consumption when in an alarmed and unalarmed states and have on, mute and test buttons. The alarm senses the status of the normally open dry relay contact (with power applied) of the connected SPD. The normally open and normally closed contacts are available for use in the installation. The audible alarm is available with other NEMA 4X options.

Standard enclosure shown; enclosure varies by model and options.

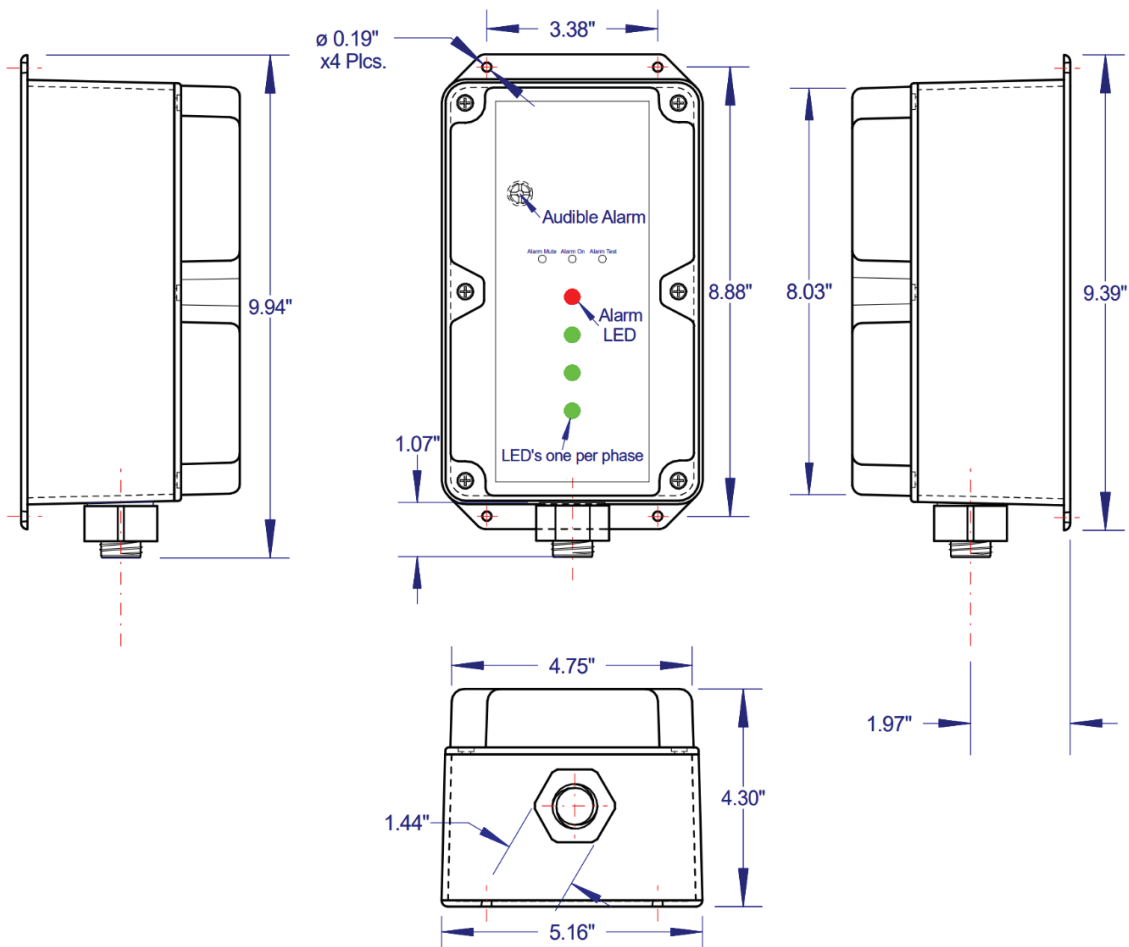

USA

PO Box 15732, Brooksville, FL 34604
 Tel 888-987-8877/850-654-5559
 Fax 850-654-3844

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE