


AC10 Option

The AC10 option is the internal audible alarm option that contains an 80 dB, 4 kHz continuous siren and a red trouble LED which activates if the unit fails. There is also one green LED per phase to show normal operation. These circuits are optimized to minimize power consumption when in an alarmed and unalarmed states. The alarm senses the status of the normally open dry relay contact (with power applied) of the connected SPD. In the case of a failure the alarm and red LED continue to operate until power is removed. The normally open and normally closed contacts are available for use in the installation. The audible alarm is available with other NEMA 4X enclosure options.

Standard enclosure shown; enclosure varies by model and options.

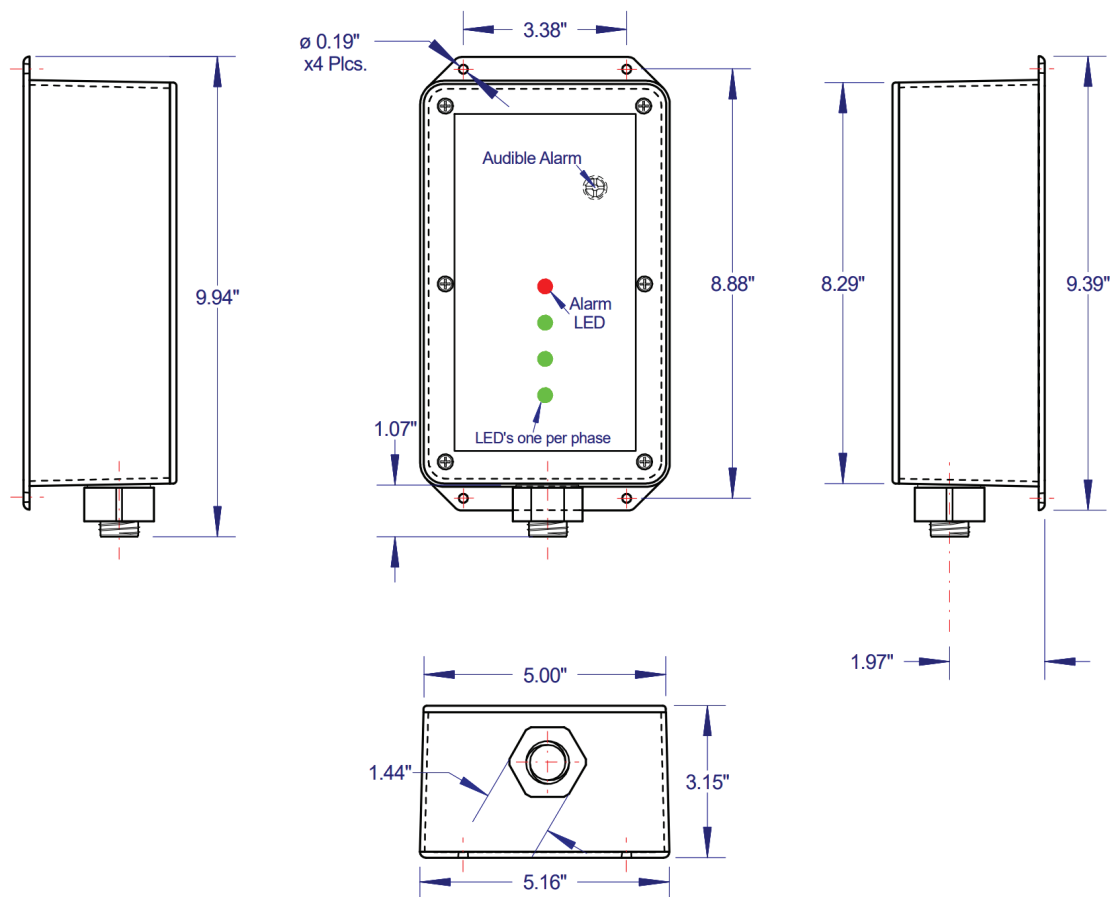

USA

PO Box 15732, Brooksville, FL 34604
 Tel 888-987-8877/850-654-5559
 Fax 850-654-3844

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE