


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Power Utilities

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

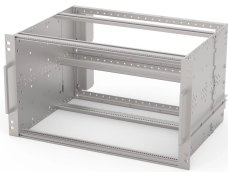

CERTIFICATIONS



FEATURES

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	For Mounting	Gasket Type	Shock and Vibration Tolerance
21500-070	6 U	36 HP	1	Backplane	Textile	5 g (force)
21500-067	3 U	36 HP	1	Backplane	Textile	5 g (force)
21500-029	3 U	84 HP	1	Backplane	Textile	5 g (force)
21500-027	6 U	84 HP	1	Backplane	Textile	5 g (force)

Table 2/2

Catalog Number	Handle Included	Mounting	Complies With	EMC Shielding	Product Type	Certifications
21500-070	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No	Subrack/Chassis	RoHS
21500-067	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No	Subrack/Chassis	RoHS
21500-029	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No	Subrack/Chassis	RoHS, SNCF
21500-027	Yes	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	No	Subrack/Chassis	RoHS, SNCF

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE