


# Novastar Base/Plinth

## Power Utilities

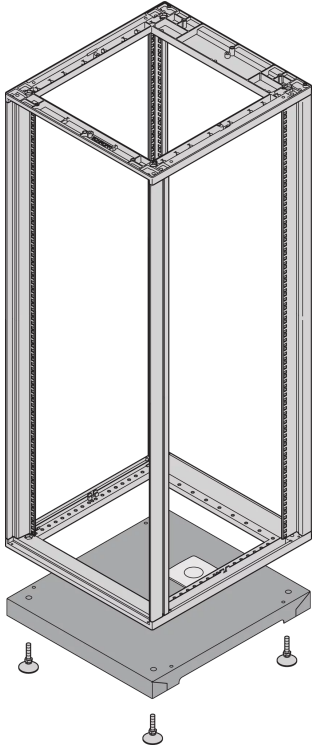

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

## CERTIFICATIONS



## FEATURES

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

SPECIFICATIONS

Table 1/1				
Catalog Number	Color	Color Code	Product Type	Type
27230-076	Black Grey	RAL 7021	Cabinet/Rack Base	Base Plinth
27230-072	Black Grey	RAL 7021	Cabinet/Rack Base	Base Plinth
27230-080	Black Grey	RAL 7021	Cabinet/Rack Base	Base Plinth
27230-070	Black Grey	RAL 7021	Cabinet/Rack Base	Base Plinth
27230-071	Black Grey	RAL 7021	Cabinet/Rack Base	Base Plinth

ADDITIONAL PRODUCT DETAILS

Please order brush strip separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE