

# Side Receptor Plug

## Power Utilities



### FEATURES

Fully encapsulated connection from conductor to receptor disk

Performance tested beyond IEC® 61400-24

Superior receptor product life performance

Less than 12 °C (54 °F) temperature rise after strike of 225 kA


Simple integrated installation

### SPECIFICATIONS

Table 1/1

| Catalog Number | Height (H) | A      |
|----------------|------------|--------|
| WT2SA7002.5    | 1.420"     | 5 3/4" |

### DIAGRAMS

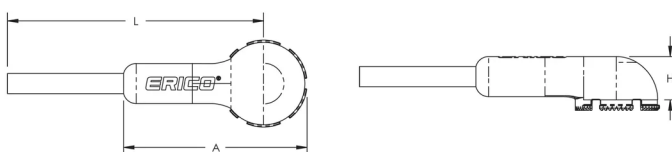

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**