

# 19" Front Panel With Holes for Handles



Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

## CERTIFICATIONS



## FEATURES

19" front panels have additional holes for mounting of handles

## SPECIFICATIONS

<b>Rack Width:</b>	95HP
<b>Material:</b>	Aluminum
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Catalog Number	Rack Height	Handle Type	Finish	Mounting	Package Quantity	Front Finish
30219-161	1U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-050	1U	Front Handle	Anodized	Screw-on Front	1	Anodized
30219-162	2U	Front Handle	Anodized	Screw-on Front	1	Anodized


CatalogNumber	Rack Height	Handle Type	Finish	Mounting	Package Quantity	Front Finish
30219-163	3U	Front Handle	Anodized	Screw-on Front	1	Anodized
30219-164	4U	Front Handle	Anodized	Screw-on Front	1	Anodized
30219-165	5U	Front Handle	Anodized	Screw-on Front	1	Anodized
30219-166	6U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-051	2U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-052	3U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-053	4U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-054	5U	Front Handle	Anodized	Screw-on Front	1	Anodized
40304-055	6U	Front Handle	Anodized	Screw-on Front	1	Anodized

Table 2/2

Catalog Number	Rear Finish	Treated Edges	EMC Shielding	Type	Quick Ship
30219-161	Anodized	No	No	19" Front Panel	No
40304-050	Anodized	Yes	No	19" Front Panel	No
30219-162	Anodized	No	No	19" Front Panel	No
30219-163	Anodized	No	No	19" Front Panel	No
30219-164	Anodized	No	No	19" Front Panel	No
30219-165	Anodized	No	No	19" Front Panel	No
30219-166	Anodized	No	No	19" Front Panel	No
40304-051	Anodized	Yes	No	19" Front Panel	No

Catalog Number	Rear Finish	Treated Edges	EMC Shielding	Type	Quick Ship
40304-052	Anodized	Yes	No	19" Front Panel	No
40304-053	Anodized	Yes	No	19" Front Panel	No
40304-054	Anodized	Yes	No	19" Front Panel	No
40304-055	Anodized	Yes	No	19" Front Panel	No

## DIAGRAMS

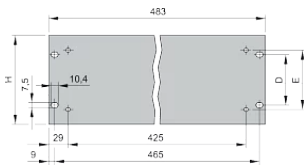

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**