

19" Front Panel

Front panels made of Aluminum.



CERTIFICATIONS



FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

SPECIFICATIONS

Rack Width:	95HP
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Catalog Number	Rack Height	Mounting	Finish	Front Finish	Package Quantity	Rear Finish
30118-948	1U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-299	1U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-098	1U	Screw-on Front	Anodized	Anodized	1	Anodized

CatalogNumber	Rack Height	Mounting	Finish	Front Finish	Package Quantity	Rear Finish
40304-074	1U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-950	3U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-302	3U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-104	3U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-076	3U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-951	4U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-303	4U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-107	4U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-077	4U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-953	6U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-305	6U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-113	6U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-079	6U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-954	7U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-306	7U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-137	7U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-080	7U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-956	9U	Screw-on Front	Powder Coated	Painted	1	Painted

CatalogNumber	Rack Height	Mounting	Finish	Front Finish	Package Quantity	Rear Finish
30118-308	9U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-143	9U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-082	9U	Screw-on Front	Anodized	Anodized	1	Anodized
30118-301	2U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-304	5U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-307	8U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-309	10U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-949	2U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-952	5U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-955	8U	Screw-on Front	Powder Coated	Painted	1	Painted
30118-957	10U	Screw-on Front	Powder Coated	Painted	1	Painted
30219-101	2U	Screw-on Front	Anodized	Anodized	1	Anodized
30219-110	5U	Screw-on Front	Powder Coated	Anodized	1	Anodized
30219-138	8U	Screw-on Front	Anodized	Anodized	1	Anodized
30219-144	10U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-075	2U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-078	5U	Screw-on Front	Anodized	Anodized	1	Anodized
40304-081	8U	Screw-on Front	Anodized	Anodized	1	Anodized

CatalogNumber	Rack Height	Mounting	Finish	Front Finish	Package Quantity	Rear Finish
40304-083	10U	Screw-on Front	Anodized	Anodized	1	Anodized

Table 2/2

Catalog Number	Treated Edges	Color Code	EMC Shielding	Type	Quick Ship
30118-948		RAL 7021	No	19" Front Panel	No
30118-299		RAL 7035	No	19" Front Panel	No
30219-098	No		No	19" Front Panel	No
40304-074	Yes		No	19" Front Panel	No
30118-950		RAL 7021	No	19" Front Panel	No
30118-302		RAL 7035	No	19" Front Panel	No
30219-104	No		No	19" Front Panel	No
40304-076	Yes		No	19" Front Panel	No
30118-951		RAL 7021	No	19" Front Panel	No
30118-303		RAL 7035	No	19" Front Panel	No
30219-107	No		No	19" Front Panel	No
40304-077	Yes		No	19" Front Panel	No
30118-953		RAL 7021	No	19" Front Panel	No
30118-305		RAL 7035	No	19" Front Panel	No
30219-113	No		No	19" Front Panel	No
40304-079	Yes		No	19" Front Panel	No


Catalog Number	Treated Edges	Color Code	EMC Shielding	Type	Quick Ship
30118-954		RAL 7021	No	19" Front Panel	No
30118-306		RAL 7035	No	19" Front Panel	No
30219-137	No		No	19" Front Panel	No
40304-080	Yes		No	19" Front Panel	No
30118-956		RAL 7021	No	19" Front Panel	No
30118-308		RAL 7035	No	19" Front Panel	No
30219-143	No		No	19" Front Panel	No
40304-082	Yes		No	19" Front Panel	No
30118-301		RAL 7035	No	19" Front Panel	No
30118-304		RAL 7035	No	19" Front Panel	No
30118-307		RAL 7035	No	19" Front Panel	No
30118-309		RAL 7035	No	19" Front Panel	No
30118-949		RAL 7021	No	19" Front Panel	No
30118-952		RAL 7021	No	19" Front Panel	No
30118-955		RAL 7021	No	19" Front Panel	No
30118-957		RAL 7021	No	19" Front Panel	No
30219-101	No		No	19" Front Panel	No
30219-110	No		No	19" Front Panel	No

Catalog Number	Treated Edges	Color Code	EMC Shielding	Type	Quick Ship
30219-138	No		No	19" Front Panel	No
30219-144	No		No	19" Front Panel	No
40304-075	Yes		No	19" Front Panel	No
40304-078	Yes		No	19" Front Panel	No
40304-081	Yes		No	19" Front Panel	No
40304-083	Yes		No	19" Front Panel	No

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

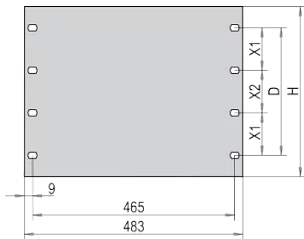

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE