


# Assembly Parts for Rugged Components

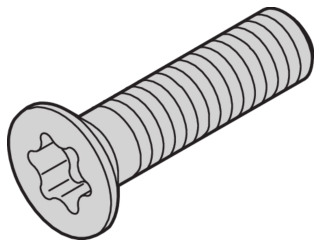

Assembly parts with thread-locking compound for rugged Side Panel, horizontal rail, cover plates, rear angle.

## CERTIFICATIONS



## FEATURES

Screws for the following fixings: Rugged side panel - horizontal rail, Rugged side panel - cover plate, Rugged side panel - rear angle

## SPECIFICATIONS

**Product Type:** Assembly Kit

**Product Family:** EuropacPRO

Table 1/2

Catalog Number	Type	Package Quantity	Thread Size	Finish	Material	Works With
24566-105	Countersunk Screw	100	M4		Stainless Steel	Subracks
24566-104	Panhead Screw	100	M4		Stainless Steel	Subracks
24566-103	Panhead Screw	100	M4		Stainless Steel	Subracks
24566-106	Countersunk Screw	100	M4		Stainless Steel	Subracks

CatalogNumber	Type	Package Quantity	Thread Size	Finish	Material	Works With
24566-101	Countersunk Screw	100	M4		Stainless Steel	Subracks
24566-102	Panhead Screw	100	M4		Stainless Steel	Subracks
24566-100	Countersunk Screw	100	M4		Stainless Steel	Subracks
24560-140	Square Nut	100		Zinc Plated	Steel	Subracks

Table 2/2

Catalog Number	Quick Ship
24566-105	No
24566-104	No
24566-103	No
24566-106	No
24566-101	No
24566-102	No
24566-100	No
24560-140	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**