


CompacPRO Complete Desktop Case, Unshielded

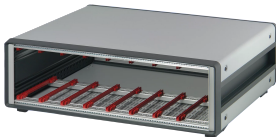

The pre-configured nVent SCHROFF CompacPRO case provides electronics protection for 19" assemblies such as plug-in units and euroboards. The aluminum die cast frame and sidepanels guarantee a robust solution. In addition an extensive accessory range is available.

CERTIFICATIONS



FEATURES

Desktop case pre-configured in accordance with IEC 60297-3-101 for 19" components

Aluminum construction ensures robust solution

Side panel with integrated handle function

For backplane mounting with insulation strips

Ventilation slots in rear panel

Ventilation slots in base plate

IP 20 in accordance with IEC 60529

Front and rear identical, depth-symmetrical construction

GND / earthing connections in accordance with (please see catalog page 5.76)

Conforms with DIN EN 62368-1

SPECIFICATIONS

Product Type:	Case
Type:	Case for 19" Components

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Frame Construction	Cooling Option	Complies With
14575-114	3U	28HP	1	Single Piece	No	IEC 60297-3-103
14575-115	3U	28HP	1	Single Piece	No	IEC 60297-3-103
14575-134	3U	42HP	1	Single Piece	No	IEC 60297-3-103
14575-135	3U	42HP	1	Single Piece	No	IEC 60297-3-103
14575-136	3U	42HP	1	Single Piece	No	IEC 60297-3-103
14575-154	3U	63HP	1	Single Piece	No	IEC 60297-3-103
14575-155	3U	63HP	1	Single Piece	No	IEC 60297-3-103
14575-156	3U	63HP	1	Single Piece	No	IEC 60297-3-103
14575-174	3U	84HP	1	Single Piece	No	IEC 60297-3-103
14575-175	3U	84HP	1	Single Piece	No	IEC 60297-3-103
14575-176	3U	84HP	1	Single Piece	No	IEC 60297-3-103
14575-178	3U	84HP	1	Single Piece	No	IEC 60297-3-103
14575-476	6U	84HP	1	Single Piece	No	IEC 60297-3-103
14575-477	6U	84HP	1	Single Piece	No	IEC 60297-3-103

Table 2/2

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
14575-114	No	Anodized, Powder Coated	Aluminum	IP20	No

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
14575-115	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-134	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-135	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-136	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-154	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-155	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-156	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-174	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-175	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-176	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-178	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-476	No	Anodized, Powder Coated	Aluminum	IP20	No
14575-477	No	Anodized, Powder Coated	Aluminum	IP20	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE