


Comptec 19" Desktop Case, Unshielded

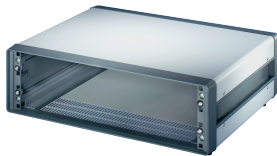

The nVent SCHROFF Comptec case is compatible with a 19" cabinet and is used to house assemblies such as 19" subracks, 19" fan trays or 19" front panels. This case is also typically used for desktop applications.

CERTIFICATIONS



FEATURES

Desktop case (pre-fitted)

Unshielded

Ventilation slits in base plate

Front and rear frames in die-cast Al

Top cover, base plate and rear panel in steel

Conforms with DIN EN 62368-1

SPECIFICATIONS

Product Type: Case
Type: Case for 19" Subrack and 19" Chassis
Product Family: Comptec

Table 1/2

Catalog Number	Rack Height	Rack Width	Material	Package Quantity	Front Frame Construction	Cooling Option
10225-613	4U	84HP	Aluminum, Steel	1	Single Piece	No

CatalogNumber	Rack Height	Rack Width	Material	Package Quantity	Front Frame Construction	Cooling Option
10225-627	7U	84HP	Aluminum, Steel	1	Single Piece	No
10225-612	3U	84HP	Aluminum, Steel	1	Single Piece	No
10225-626	6U	84HP	Aluminum, Steel	1	Single Piece	No
10225-629	9U	84HP	Aluminum, Steel	1	Single Piece	No
10225-637	6U	84HP	Aluminum, Steel	1	Single Piece	No
10225-624	4U	84HP	Aluminum, Steel	1	Single Piece	No
10225-638	7U	84HP	Aluminum, Steel	1	Single Piece	No
10225-604	6U	84HP	Aluminum, Steel	1	Single Piece	No
10225-640	9U	84HP	Aluminum, Steel	1	Single Piece	No
10225-667	9U	84HP	Aluminum	1	Single Piece	No
10225-623	3U	84HP	Aluminum, Steel	1	Single Piece	No
10225-670	12U	84HP	Aluminum	1	Single Piece	No
10225-602	4U	84HP	Aluminum, Steel	1	Single Piece	No
10225-682	9U	84HP	Aluminum	1	Single Piece	No
10225-618	9U	84HP	Aluminum, Steel	1	Single Piece	No
10225-615	6U	84HP	Aluminum, Steel	1	Single Piece	No
10225-696	12U	84HP	Aluminum	1	Single Piece	No
10225-601	3U	84HP	Aluminum, Steel	1	Single Piece	No

CatalogNumber	Rack Height	Rack Width	Material	Package Quantity	Front Frame Construction	Cooling Option
10225-616	7U	84HP	Aluminum, Steel	1	Single Piece	No
10225-685	12U	84HP	Aluminum	1	Single Piece	No
10225-693	9U	84HP	Aluminum	1	Single Piece	No

Table 2/2					
Catalog Number	Complies With	EMC Shielding	Finish	Protection Rating	Quick Ship
10225-613	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-627	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-612	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-626	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-629	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-637	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-624	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-638	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-604	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-640	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-667	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-623	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-670	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-602	IEC 60297-3-100	No	Powder Coated	IP20	No

Catalog Number	Complies With	EMC Shielding	Finish	Protection Rating	Quick Ship
10225-682	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-618	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-615	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-696	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-601	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-616	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-685	IEC 60297-3-100	No	Powder Coated	IP20	No
10225-693	IEC 60297-3-100	No	Powder Coated	IP20	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE