


Connection clamp with levers

Distribution Clamps for Distribution Box.

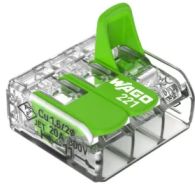

FEATURES

Connection clamp with levers

For all conductor types

3 or 5 conductors

Up to 4.00 mm²

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Color	Clamp Quantity	Depth	Height	Material
20118-902	Clamp	Transparent, Green	3	0.74in	0.33in	Polycarbonate
20118-903	Clamp	Transparent, Green	5	0.74in	0.33in	Polycarbonate

Table 2/2

Catalog Number	Max Current	Max Voltage	Package Quantity	Weight	Width	Quick Ship
20118-902	20A	600V	10	0.006lb	0.74in	No
20118-903	20A	600V	10	0.009lb	1.18in	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE