
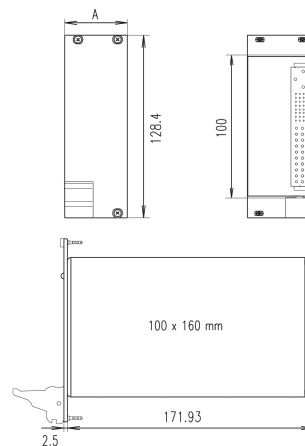


PSU 19" for CompactPCI, DC/DC, 3 U, 8 HP

CATALOG NUMBER

13100-142

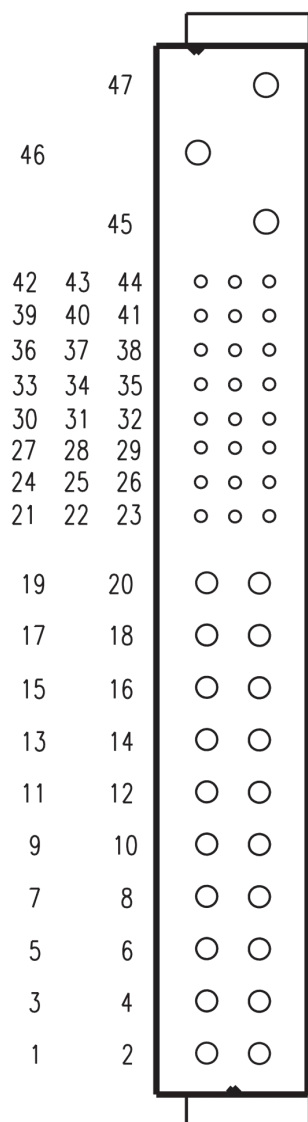

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

CERTIFICATIONS



FEATURES

- Connector P47 and CompactPCI signalling
- 4 output voltages
- Redundant operation with Current Share Bus (CSB), hot-swap

PRODUCT ATTRIBUTES

- Product Type: Power Supply
- Type: 19" DC/DC Converter
- Works With: CompactPCI and VME64x
- Input Voltage DC: 36 – 75V
- Power: 250W
- Number of Output Voltages: 4
- Voltage 1: 5V
- Current 1: 40A
- Voltage 2: 3.3V
- Current 2: 40A
- Voltage 3: 12V
- Current 3: 5.5A
- Voltage 4: -12V
- Current 4: 2A
- Rack Height: 3U
- Rack Width: 8HP
- Net Weight: 0.94kg
- Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE