


Mounting Plate for 19" Case and Subrack, 63 HP, 220 mm Board Length

CATALOG NUMBER

34562-751

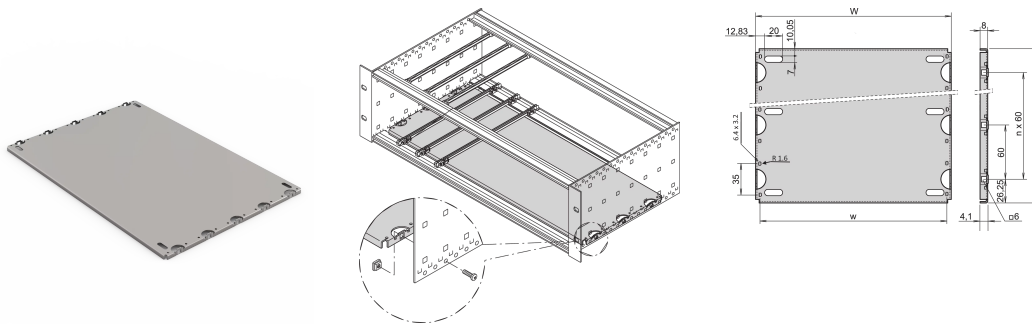

Material	HP	W	w	D
34562745	28	146,87	137,16	112,50
34562749	28	146,87	137,16	172,50
34562753	28	146,87	137,16	232,50
34562757	28	146,87	137,16	292,50
34562746	42	217,99	208,28	112,50
34562750	42	217,99	208,28	172,50
34562754	42	217,99	208,28	232,50
34562758	42	217,99	208,28	292,50
34562747	63	324,67	314,96	112,50
34562751	63	324,67	314,96	172,50
34562755	63	324,67	314,96	232,50
34562759	63	324,67	314,96	292,50
34562748	84	431,35	421,64	112,50
34562752	84	431,35	421,64	172,50
34562756	84	431,35	421,64	232,50
34562760	84	431,35	421,64	292,50
34562870	84	431,35	421,64	352,50
34562871	84	431,35	421,64	412,50

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



FEATURES

- For assembly of heavy components
- Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels
- Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip
- The chassis plate can't be combined with EMC top- / bottom covers

PRODUCT ATTRIBUTES

- Rack Width: 63HP
- Package Quantity: 1
- Material: Aluminum
- Product Family: EuropacPRO; RatiopacPRO; CompacPRO; PropacPRO
- Product Type: Mounting Plate
- Works With: Subracks
- Net Weight: 0.28kg

ADDITIONAL PRODUCT DETAILS

- Please order assembly kit for mounting plate separately.
- Other versions on request.
- Fixing strips required for partial width, please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	+971.4.378.1700
Chat with us:	Betschdorf, France	Qingdao, China	Bangalore, India
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	+91.80.6715.2001
	Warsaw, Poland	Singapore	Istanbul, Turkey
	+48.22.209.98.35	+65.6768.5800	+90.216.250.7374
	Assago, Italy	Shin-Yokohama, Japan	Chat with us:
	+39.02.932.7141	+81.45.476.0271	nvent.com/schroff
	Chat with us:	Chat with us:	
	nvent.com/schroff	nvent.com/schroff	



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE