


# Frame Type Plug-In Unit Front Panel, Unshielded, 6 U, 12 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

**CATALOG NUMBER**

**34812-612**

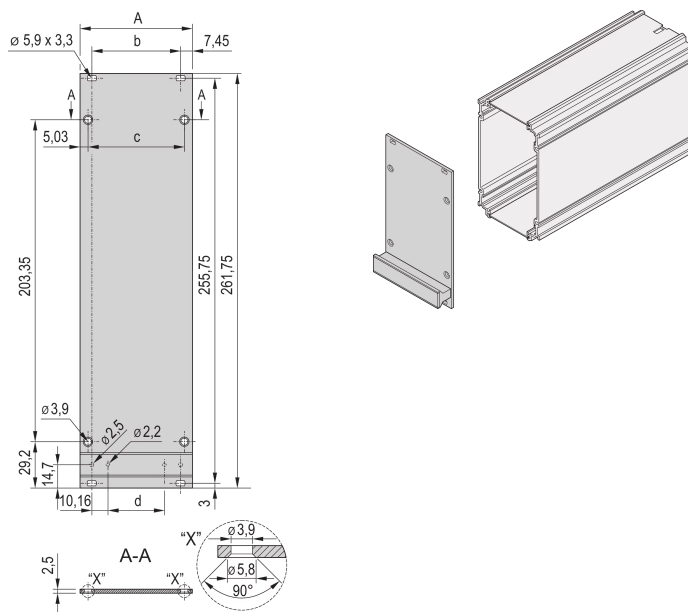

Front Panel for frame type plug-in unit, shieldable.

## CERTIFICATIONS



## FEATURES

Al, 2.5 mm, front anodized, rear anodized, cut edges blank

## Front Panel for frame type plug-in units PRO

## PRODUCT ATTRIBUTES


|                             |
|-----------------------------|
| Rack Width: 12HP            |
| Accessory Type: Front panel |
| Package Quantity: 1         |
| Front Finish: Anodized      |
| Rear Finish: Conductive     |
| Treated Edges: No           |
| Finish: Anodized            |
| Material: Aluminum          |
| Product Type: Front Panel   |
| Rack Height: 6U             |
| Net Weight: 0.1kg           |

## ADDITIONAL PRODUCT DETAILS

Mounting kit to fix front Panel to plug-in unit, handle to bolt on, clip and screw with plastic sleeve for mounting plug-in unit in subrack or case are included in the item 'Mounting kit for five plug-in units', part number 24812-100. The handle is available in 2 colors (grey or black). Individual parts 100 pieces. Screw for fixing front Panel to plug-in unit, part no. 24812-501. Screw for mounting handle, part no. 24560-179 Clip - mounting aid for handle, part no. 21101-239. Screw for sleeve, threaded insert front inserted into horizontal rail, part no. 21100-748. Screw for sleeve, threaded insert rear inserted into horizontal rail, part no. 21101-101. Sleeve 21100-660, 21100-661, 21100 - 662, 21100-886, 21100-146.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## DIAGRAMS

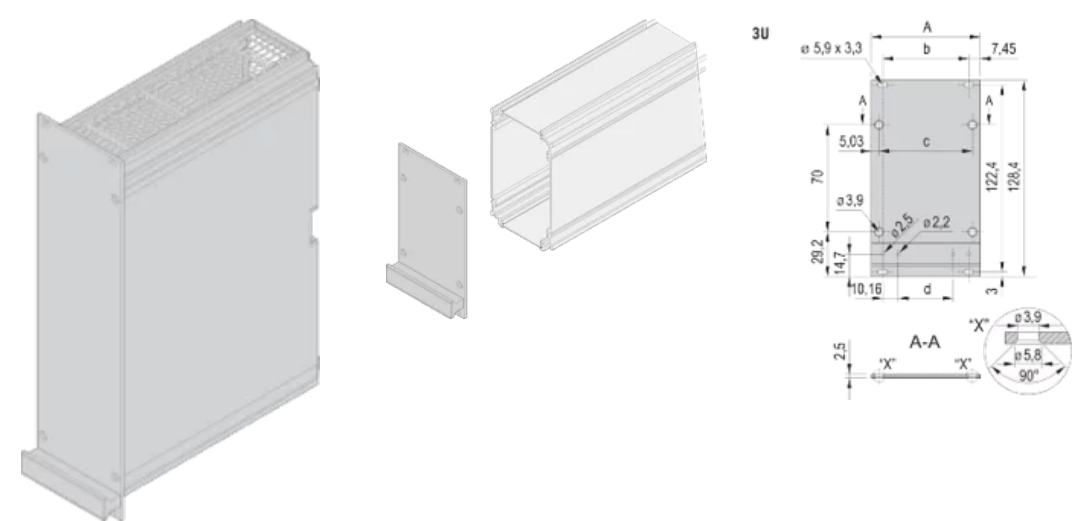

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**