


Connector Type C, EN 60603, DIN 41612, for Ribbon Cable

CATALOG NUMBER

69005-596

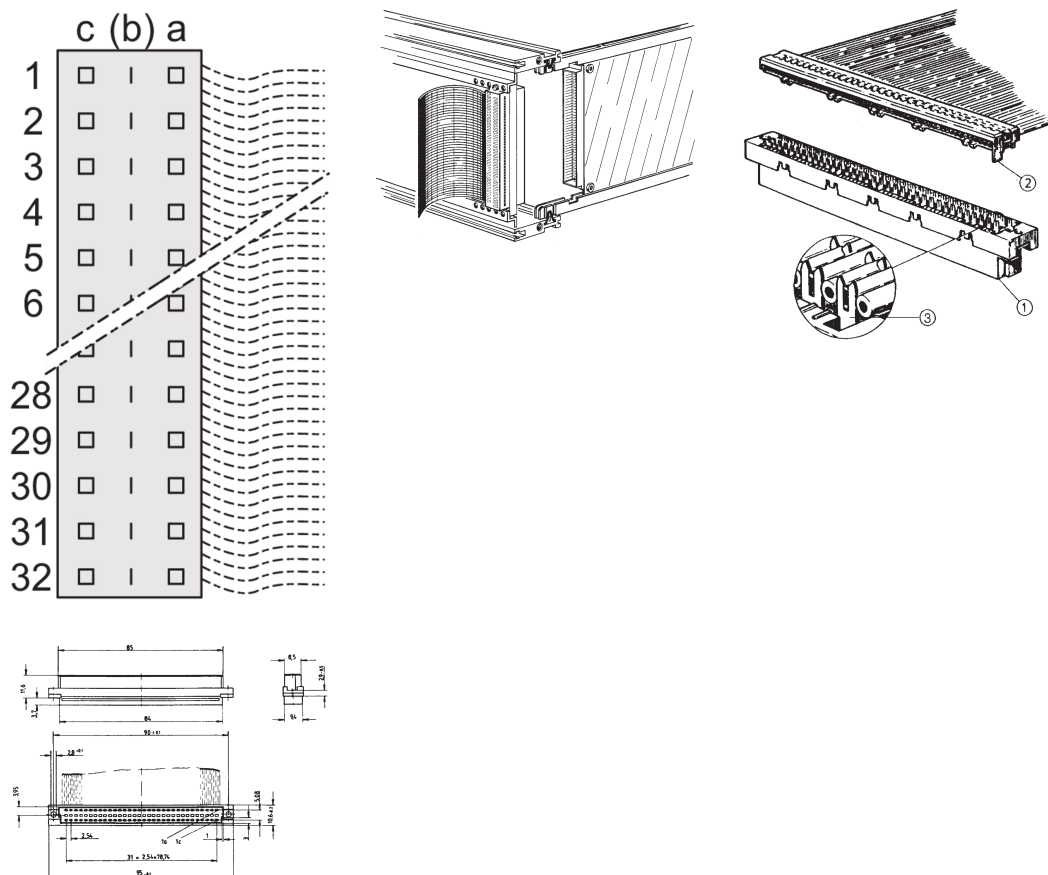

Male / Female DIN connector form C. Requirement class 2 as per EN 60603 (DIN 41642), Version with ribbon cable.

CERTIFICATIONS



FEATURES

Requirement class 2 as per EN 60603 (DIN 41642)

Female connector, type C, complying with IEC 60603-2 / IEC 41612

Cut and clamp technique

For type C64, 64 pins

Separate coding

PRODUCT ATTRIBUTES

Product Type: Connector

Type: Ribbon Cable

Works With: Front Panels

Number of Contacts: 64

Contact Material: Gold Plated

Max Current @ 20°C: 1A

Test Voltage (Ueff), Contact-Contact: 1kV

Row Assignment: A; C

Finish: Gold Plated

Gross Weight: 0.019kg

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE