


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

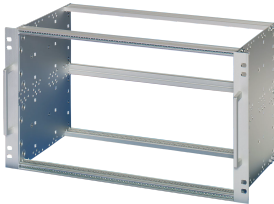

CERTIFICATIONS



FEATURES

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

SPECIFICATIONS

Material:	Aluminum
EMC Shielding:	No
Product Type:	Subrack/Chassis

Table 1/2

Catalog Number	Rack Height	Package Quantity	Depth	For Mounting	Gasket Type	Shock and Vibration Tolerance
21500-077	3U	1	9.25in	Backplane	Textile EMC	5g (force)
21500-078	6U	1	9.25in	Backplane	Textile EMC	5g (force)

Table 2/2

Catalog Number	Handle Included	Mounting	Complies With	Finish	Rack Width	Quick Ship
21500-077	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP	No
21500-078	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP	No

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE