


# EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

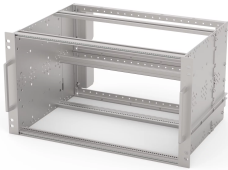

## CERTIFICATIONS



## FEATURES

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Complies With:</b>	IEC 60297-3-103; SNCF NFF 61005; SNCF NFF 60002

**EMC Shielding:** No  
**Product Type:** Subrack/Chassis

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Depth	For Mounting	EMC Gasket Type
21500-027	6U	84HP	1	12.6in	Backplane	Textile
21500-029	3U	84HP	1	12.6in	Backplane	Textile
21500-067	3U	36HP	1	12.6in	Backplane	Textile
21500-070	6U	36HP	1	12.6in	Backplane	Textile

Table 2/2

Catalog Number	Shock and Vibration Tolerance	Handle Included	Mounting	Certifications	Quick Ship
21500-027	5g (force)	Yes	Rack	SNCF, RoHS	No
21500-029	5g (force)	Yes	Rack	RoHS, SNCF	No
21500-067	5g (force)	Yes	Rack	RoHS	No
21500-070	5g (force)	Yes	Rack	RoHS	No

## ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**