


EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

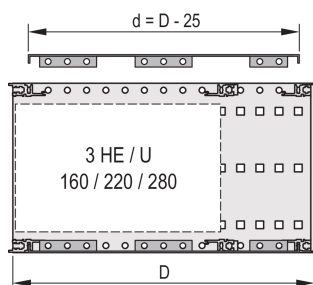

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

CERTIFICATIONS



FEATURES

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

SPECIFICATIONS

Material:	Aluminum
Product Type:	Cover Plate
Product Family:	EuropacPRO
Finish:	Passivated
Type:	Perforated
Works With:	Sub racks

Table 1/1

Catalog Number	Rack Width	Package Quantity	Package Unit	Quick Ship
----------------	------------	------------------	--------------	------------

24563-560	42HP	2	Pair	No
24563-556	36HP	2	Pair	No
24563-660	63HP	2	Pair	No
24563-760	84HP	2	Pair	No
24563-761	84HP	2	Pair	No
24563-762	84HP	2	Pair	No
24563-764	84HP	2	Pair	No
24563-766	84HP	2	Pair	No
24563-765	84HP	2	Pair	No
24563-555	36HP	2	Pair	No
24563-561	42HP	2	Pair	No
24563-562	42HP	2	Pair	No
24563-563	42HP	2	Pair	No
24563-564	42HP	2	Pair	No
24563-661	63HP	2	Pair	No
24563-662	63HP	2	Pair	No
24563-663	63HP	2	Pair	No
24563-763	84HP	2	Pair	No
24563-767	84HP	2	Pair	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE