

Front Panel, Anodized, Unshielded, Screw Assembly

Anodized front panel, unshielded version, Al, 2.5 mm.



CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm

Al, anodized

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
30807-416	2U	84HP	1	Screw-on Front	Anodized	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
30807-481	3U	4HP	1	Screw-on Front	Anodized	Anodized
30807-482	3U	6HP	1	Screw-on Front	Anodized	Anodized
30807-483	3U	10HP	1	Screw-on Front	Anodized	Anodized
30807-484	3U	8HP	1	Screw-on Front	Anodized	Anodized
30807-485	3U	12HP	1	Screw-on Front	Anodized	Anodized
30807-487	3U	21HP	1	Screw-on Front	Anodized	Anodized
30807-494	3U	42HP	1	Screw-on Front	Anodized	Anodized
30807-496	3U	28HP	1	Screw-on Front	Anodized	Anodized
30807-501	3U	14HP	1	Screw-on Front	Anodized	Anodized
30807-506	3U	84HP	1	Screw-on Front	Anodized	Anodized
30807-508	3U	3HP	1	Screw-on Front	Anodized	Anodized
30807-509	3U	7HP	1	Screw-on Front	Anodized	Anodized
30807-510	3U	5HP	1	Screw-on Front	Anodized	Anodized
30807-596	4U	84HP	1	Screw-on Front	Anodized	Anodized
30807-752	6U	6HP	1	Screw-on Front	Anodized	Anodized
30807-753	6U	10HP	1	Screw-on Front	Anodized	Anodized
30807-755	6U	12HP	1	Screw-on Front	Anodized	Anodized
30807-757	6U	21HP	1	Screw-on Front	Anodized	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
30807-758	6U	14HP	1	Screw-on Front	Anodized	Anodized
30807-764	6U	42HP	1	Screw-on Front	Anodized	Anodized
30807-766	6U	28HP	1	Screw-on Front	Anodized	Anodized
30807-771	6U	63HP	1	Screw-on Front	Anodized	Anodized
30807-776	6U	84HP	1	Screw-on Front	Anodized	Anodized
30807-777	6U	5HP	1	Screw-on Front	Anodized	Anodized
30807-778	6U	4HP	1	Screw-on Front	Anodized	Anodized
30807-779	6U	8HP	1	Screw-on Front	Anodized	Anodized
30807-780	6U	16HP	1	Screw-on Front	Anodized	Anodized
30807-833	6U	7HP	1	Screw-on Front	Anodized	Anodized
30808-067	3U	63HP	1	Screw-on Front	Anodized	Anodized
30810-432	3U	2HP	1	Screw-on Front	Anodized	Anodized
30818-741	6U	2HP	1	Screw-on Front	Anodized	Anodized

Table 2/2

Catalog Number	Treated Edges	Complies With	EMC Shielding	Certifications	Quick Ship
30807-416	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-481	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-482	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-483	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No


Catalog Number	Treated Edges	Complies With	EMC Shielding	Certifications	Quick Ship
30807-484	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-485	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-487	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-494	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-496	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-501	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-506	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-508	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-509	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-510	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-596	Yes	IEC 60297-3-101, IEEE 1101.1/10	No		No
30807-752	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-753	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-755	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-757	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-758	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-764	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-766	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No

Catalog Number	Treated Edges	Complies With	EMC Shielding	Certifications	Quick Ship
30807-771	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-776	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-777	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-778	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-779	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-780	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30807-833	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30808-067	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30810-432	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No
30818-741	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	RoHS	No

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

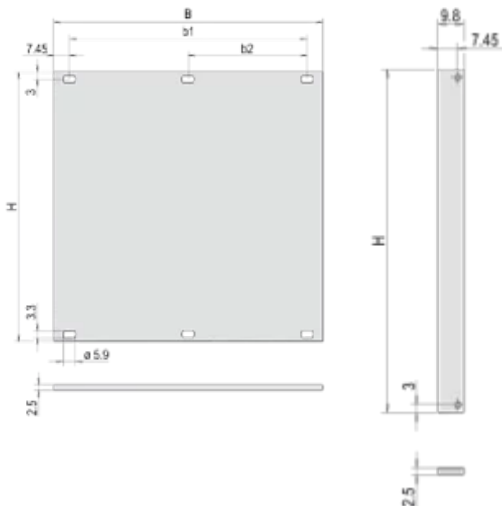

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE