


Front Panel, Full Width, Slotted, Unshielded, for RatiopacPRO

Full-width front panel, slotted, unshielded.

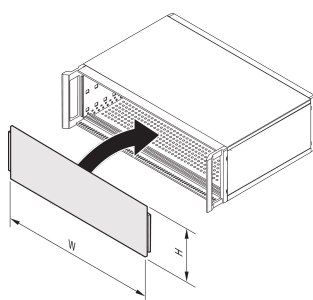

CERTIFICATIONS



FEATURES

Inserted between side panel and molded parts such as trim, 19" mounting bracket or handle

Front panels can also be used as rear panels

Fixes without screws (special horizontal rails cover the edges of the front panel and hold them in place)

Shielded (rear conductive); for a conductive connection with the case please order EMC sealing (stainless steel) separately

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
34571-605	3U	28HP	1	Anodized	Conductive	No

CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
34571-606	3U	42HP	1	Anodized	Conductive	No
34571-607	3U	63HP	1	Anodized	Conductive	No
34571-608	3U	84HP	1	Anodized	Conductive	No
34571-609	4U	28HP	1	Anodized	Conductive	No
34571-610	4U	42HP	1	Anodized	Conductive	No
34571-611	4U	63HP	1	Anodized	Conductive	No
34571-612	4U	84HP	1	Anodized	Conductive	No
34571-613	6U	28HP	1	Anodized	Conductive	No
34571-614	6U	42HP	1	Anodized	Conductive	No
34571-615	6U	63HP	1	Anodized	Conductive	No
34571-616	6U	84HP	1	Anodized	Conductive	No
34571-617	2U	28HP	1	Anodized	Conductive	No
34571-621	5U	28HP	1	Anodized	Conductive	No
34571-622	5U	42HP	1	Anodized	Conductive	No
34571-623	5U	63HP	1	Anodized	Conductive	No
34571-624	5U	84HP	1	Anodized	Conductive	No
34571-618	2U	42HP	1	Anodized	Conductive	No
34571-619	2U	63HP	1	Anodized	Conductive	No


CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
34571-620	2U	84HP	1	Anodized	Conductive	No

Table 2/2

Catalog Number	Quick Ship
34571-605	No
34571-606	No
34571-607	No
34571-608	No
34571-609	No
34571-610	No
34571-611	No
34571-612	No
34571-613	No
34571-614	No
34571-615	No
34571-616	No
34571-617	No
34571-621	No
34571-622	No
34571-623	No

Catalog Number	Quick Ship
34571-624	No
34571-618	No
34571-619	No
34571-620	No

DIAGRAMS

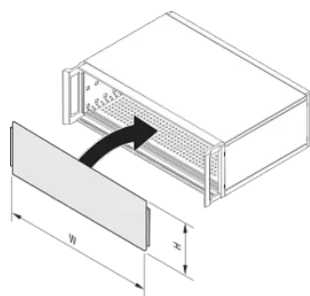

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE