


Interscale Mounting Plate With Built-In Fan Holder and Fans

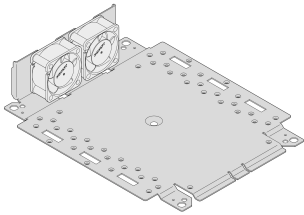

Interscale mounting plate with built-in fan holder and fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m3/h.

FEATURES

Mounting plate (raised 4 mm) with integrated fan holder including fan kit for perforated case versions

Fans are simple to fit to the mounting plate using vibrationdamping fixing material

Mounting plate fixes into desktop case with 4 plastic feet or into 19" case with 4 screws

For technical data of fans, please see delivery includes

SPECIFICATIONS

Finish: Aluminum-Zinc Plated

Product Type: Mounting Plate

Table 1/2

Catalog Number	Package Quantity	Material	Product Family	Rack Width	Type	Works With
24827-154	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-155	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-175	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-195	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases

CatalogNumber	Package Quantity	Material	Product Family	Rack Width	Type	Works With
24827-197	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-254	1	Steel	Interscale		Mounting Plate	
24827-255	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-275	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-295	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-297	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-375	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-395	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-397	1	Steel	Interscale		Mounting Plate	Small Form Factor Cases
24827-105	1	Steel	Interscale	19HP	Mounting Plate	Small Form Factor Cases
24827-107	1	Steel	Interscale	19HP	Mounting Plate	Small Form Factor Cases
24827-205	1	Steel				
24827-207	1	Steel				
24827-305	1	Steel				
24827-307	1	Steel				

Table 2/2

Catalog Number	Quick Ship
24827-154	No
24827-155	No

Catalog Number	Quick Ship
24827-175	No
24827-195	No
24827-197	No
24827-254	No
24827-255	No
24827-275	No
24827-295	No
24827-297	No
24827-375	No
24827-395	No
24827-397	No
24827-105	No
24827-107	No
24827-205	No
24827-207	No
24827-305	No
24827-307	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE