


Novastar 19" Panel/Slide Mount

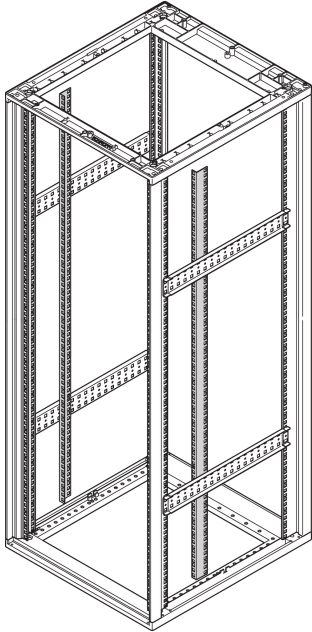

Novastar 19" Panel/Slide Mount Kit with load capacity of 400 kg, ensures easy fitting of 19" components to depth members.

CERTIFICATIONS



FEATURES

For recessed installation of 19" components

For fitting to depth members (25 mm grid)

Load carrying capacity 400 kg

SPECIFICATIONS

Product Type: Slide Mount

Material: Steel

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Finish	Package Unit
27230-172	6U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-173	9U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-174	12U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-175	16U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-176	20U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-177	25U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-197	29U	2	Black Grey	RAL 7021	Powder Coated	
27230-178	34U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-179	38U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-180	43U	2	Black Grey	RAL 7021	Powder Coated	Pair
27230-181	47U	2	Black Grey	RAL 7021	Powder Coated	Pair

Table 2/2

Catalog Number	Certifications	Quick Ship
27230-172	RoHS	No
27230-173	RoHS	No
27230-174	RoHS	No
27230-175	RoHS	No
27230-176	RoHS	No

Catalog Number	Certifications	Quick Ship
27230-177	RoHS	No
27230-197		No
27230-178	RoHS	No
27230-179	RoHS	No
27230-180	RoHS	No
27230-181	RoHS	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE