


Novastar Steel Door

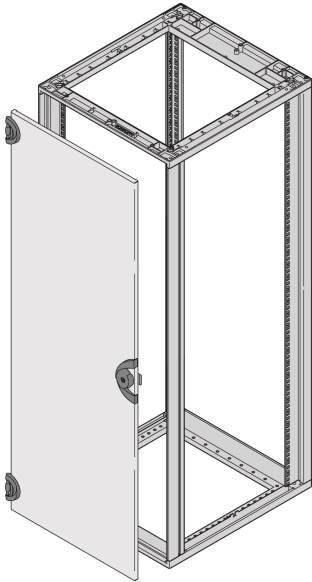

CERTIFICATIONS



FEATURES

St, 1.5 mm

Opening angle 180°, incl. grounding

Can be assembled at front and rear

Lock (2233x) with key

SPECIFICATIONS

Product Type: Cabinet Door

Material: Steel

Table 1/2

Catalog Number	Color	Color Code	Finish	Package Quantity	Rack Height	Type
25230-020	Black Grey	RAL 7021	Powder Coated	1	6U	Steel Door
25230-021	Black Grey	RAL 7021	Powder Coated	1	9U	Steel Door
25230-022	Black Grey	RAL 7021	Powder Coated	1	12U	Steel Door
25230-023	Black Grey	RAL 7021	Powder Coated	1	16U	Steel Door
25230-024	Black Grey	RAL 7021	Powder Coated	1	20U	Steel Door
25230-025	Black Grey	RAL 7021	Powder Coated	1	25U	Steel Door
25230-026	Black Grey	RAL 7021	Powder Coated	1	34U	Steel Door
25230-027	Black Grey	RAL 7021	Powder Coated	1	38U	Steel Door
25230-028	Black Grey	RAL 7021	Powder Coated	1	43U	Steel Door
25230-029	Black Grey	RAL 7021	Powder Coated	1	47U	Steel Door
25230-030	Black Grey	RAL 7021	Powder Coated	1	29U	Steel Door
26230-020	Light Grey	RAL 7035	Powder Coated	1	6U	Steel Door
26230-021	Light Grey	RAL 7035	Powder Coated	1	9U	Steel Door
26230-022	Light Grey	RAL 7035	Powder Coated	1	12U	Steel Door
26230-023	Light Grey	RAL 7035	Powder Coated	1	16U	Steel Door
26230-024	Light Grey	RAL 7035	Powder Coated	1	20U	Steel Door
26230-025	Light Grey	RAL 7035	Powder Coated	1	25U	Steel Door
26230-026	Light Grey	RAL 7035	Powder Coated	1	34U	Steel Door

CatalogNumber	Color	Color Code	Finish	Package Quantity	Rack Height	Type
26230-027	Light Grey	RAL 7035	Powder Coated	1	38U	Steel Door
26230-028	Light Grey	RAL 7035	Powder Coated	1	43U	Steel Door
26230-029	Light Grey	RAL 7035	Powder Coated	1	47U	Steel Door
26230-030	Light Grey	RAL 7035	Powder Coated	1	29U	Steel Door

Table 2/2

Catalog Number	Quick Ship
25230-020	No
25230-021	No
25230-022	No
25230-023	No
25230-024	No
25230-025	No
25230-026	No
25230-027	No
25230-028	No
25230-029	No
25230-030	No
26230-020	No
26230-021	No

Catalog Number	Quick Ship
26230-022	No
26230-023	No
26230-024	No
26230-025	No
26230-026	No
26230-027	No
26230-028	No
26230-029	No
26230-030	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE