


# Panhead Screw, Pozidrive

Panhead Screw, Pozidrive.

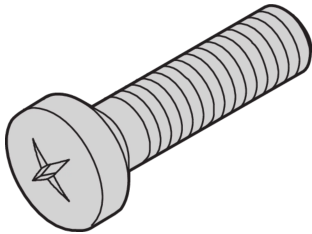

## CERTIFICATIONS



## FEATURES

Panhead screw, pozidrive

## SPECIFICATIONS

**Product Type:** Screw

**Material:** Steel

Table 1/2

| Catalog Number | Finish        | Package Quantity | Thread Size | Product Family | Type          | Works With                   |
|----------------|---------------|------------------|-------------|----------------|---------------|------------------------------|
| 21102-024      | Zinc Plated   | 100              | M3          |                | Panhead Screw |                              |
| 21120-150      | Zinc Plated   | 100              | M5          |                | Coding Block  | Cabinet                      |
| 21101-314      | Nickel Plated | 100              | M2.5        |                | Panhead Screw | Backplanes,<br>Test Adapters |

| CatalogNumber | Finish        | Package Quantity | Thread Size | Product Family  | Type          | Works With  |
|---------------|---------------|------------------|-------------|---|---------------|---|
| 21100-021     | Zinc Plated   | 50               | M6          | EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO | Panhead Screw | Front Panels, Eurorack, Novastar, Varistar, Varistar CP |
| 21100-022     | Zinc Plated   | 100              | M6          | EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO | Panhead Screw | Front Panels, Eurorack, Novastar, Varistar, Varistar CP |
| 21100-650     | Zinc Plated   | 100              | M6          | EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO | Panhead Screw | Front Panels, Eurorack, Novastar, Varistar, Varistar CP |
| 21120-202     | Zinc Plated   | 50               | M6          |   | Panhead Screw | Front Panels, Eurorack, Novastar, Varistar, Varistar CP |
| 21120-203     | Zinc Plated   | 100              | M6          |   | Panhead Screw | Front Panels, Eurorack, Novastar, Varistar, Varistar CP |
| 21101-219     | Nickel Plated | 100              | M2.5        | Frame Type Plug-In Unit   | Panhead Screw | Backplanes, Test Adapters                               |
| 21101-069     | Nickel Plated | 100              | M2.5        | Frame Type Plug-In Unit   | Panhead Screw | Backplanes, Test Adapters                               |
| 21101-220     | Nickel Plated | 100              | M2.5        | Frame Type Plug-In Unit   | Panhead Screw | Backplanes, Test Adapters                               |
| 21100-788     | Zinc Plated   | 100              | M5          | EuropacPRO  | Panhead Screw | Subracks  |
| 21101-221     | Nickel Plated | 100              | M2.5        | Frame Type Plug-In Unit   | Panhead Screw | Backplanes, Test Adapters                               |

| CatalogNumber | Finish        | Package Quantity | Thread Size | Product Family          | Type          | Works With                |
|---------------|---------------|------------------|-------------|-------------------------|---------------|---------------------------|
| 21101-222     | Nickel Plated | 100              | M2.5        | Frame Type Plug-In Unit | Panhead Screw | Backplanes, Test Adapters |

Table 2/2

| Catalog Number | Thread Type | Certifications | Quick Ship |
|----------------|-------------|----------------|------------|
| 21102-024      | Metric      | RoHS           | No         |
| 21120-150      |             | RoHS           | No         |
| 21101-314      |             | RoHS           | No         |
| 21100-021      |             | RoHS           | No         |
| 21100-022      |             | RoHS           | No         |
| 21100-650      |             | RoHS           | No         |
| 21120-202      |             |                | No         |
| 21120-203      |             |                | No         |
| 21101-219      |             | RoHS           | No         |
| 21101-069      |             | RoHS           | No         |
| 21101-220      |             | RoHS           | No         |
| 21100-788      |             | RoHS           | No         |
| 21101-221      |             | RoHS           | No         |
| 21101-222      |             | RoHS           | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**