


# PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

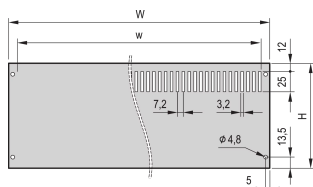

## CERTIFICATIONS



## FEATURES

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized
<b>Works With:</b>	Cases
<b>Product Family:</b>	PropacPRO
<b>Type:</b>	Rear Panel
<b>Product Type:</b>	Side Panel

Table 1/1

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-044	2U	42HP	Non-Perforated	1	No
24576-144	2U	42HP	Perforated	1	No
24576-045	2U	63HP	Non-Perforated	1	No

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-145	2U	63HP	Perforated	1	No
24576-047	3U	28HP	Non-Perforated	1	No
24576-147	3U	28HP	Perforated	1	No
24576-048	3U	42HP	Non-Perforated	1	No
24576-148	3U	42HP	Perforated	1	No
24576-049	3U	63HP	Non-Perforated	1	No
24576-149	3U	63HP	Perforated	1	No
24576-050	3U	84HP	Non-Perforated	1	No
24576-150	3U	84HP	Perforated	1	No
24576-052	4U	42HP	Non-Perforated	1	No
24576-152	4U	42HP	Perforated	1	No
24576-053	4U	63HP	Non-Perforated	1	No
24576-153	4U	63HP	Perforated	1	No
24576-054	4U	84HP	Non-Perforated	1	No
24576-154	4U	84HP	Perforated	1	No
24576-058	6U	84HP	Non-Perforated	1	No
24576-158	6U	84HP	Perforated	1	No
24576-046	2U	84HP	Non-Perforated	1	No

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-146	2U	84HP	Perforated	1	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE