


PSU Front Panel

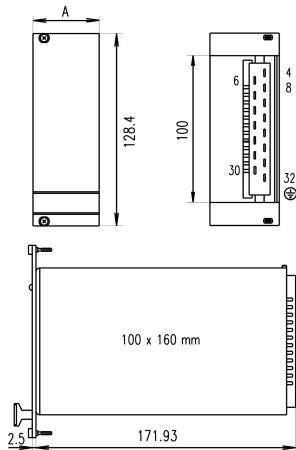

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

CERTIFICATIONS



FEATURES

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

SPECIFICATIONS

Accessory Type: Front panel

Table 1/2

Catalog Number	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Rack Width
21006-943	Aluminum	Anodized	Conductive	No	3U	6HP
21006-945	Aluminum	Anodized	Conductive	No	3U	8HP

CatalogNumber	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Rack Width
21006-954	Aluminum	Anodized	Conductive	No	3U	6HP
21006-959	Aluminum	Anodized	Conductive	No	3U	3HP
31006-677	Aluminum	Anodized	Conductive	No	3U	8HP
21006-955	Aluminum	Anodized	Conductive	No	3U	6HP
21006-956	Aluminum	Anodized	Conductive	No	3U	6HP
21006-957	Aluminum	Anodized	Conductive	No	3U	6HP
21005-475	Aluminum	Anodized	Conductive	No	3U	6HP
21005-473	Aluminum	Anodized	Conductive	No	3U	10HP
21005-474	Aluminum	Anodized	Conductive	No	3U	14HP
21005-476	Aluminum	Anodized	Conductive	No	3U	6HP
21005-477	Aluminum	Anodized	Conductive	No	3U	10HP
21005-478	Aluminum	Anodized	Conductive	No	3U	14HP
21005-470	Aluminum	Anodized	Conductive	No	3U	6HP
21005-451	Aluminum	Anodized	Conductive	No	3U	10HP
21005-439	Aluminum	Anodized	Conductive	No	3U	14HP

Table 2/2

Catalog Number	Package Quantity	Finish	Quick Ship
21006-943	1	Anodized	No
21006-945	1	Anodized	No

Catalog Number	Package Quantity	Finish	Quick Ship
21006-954	1	Anodized	No
21006-959	1	Anodized	No
31006-677	1	Anodized	No
21006-955	1	Anodized	No
21006-956	1	Anodized	No
21006-957	1	Anodized	No
21005-475	1	Anodized	No
21005-473	1	Anodized	No
21005-474	1	Anodized	No
21005-476	1	Anodized	No
21005-477	1	Anodized	No
21005-478	1	Anodized	No
21005-470	1	Anodized	No
21005-451	1	Anodized	No
21005-439	1	Anodized	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE