


RatiopacPRO EMC Front Panel, Slotted, Shielded

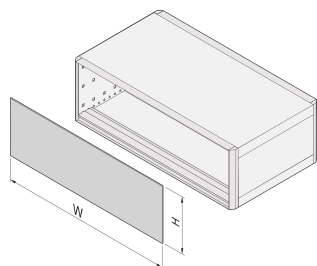

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

CERTIFICATIONS



FEATURES

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-603	3U	28HP	1	Anodized	Conductive	No
24572-604	3U	42HP	1	Anodized	Conductive	No

CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-605	3U	63HP	1	Anodized	Conductive	No
24572-606	3U	84HP	1	Anodized	Conductive	No
24572-607	4U	28HP	1	Anodized	Conductive	No
24572-608	4U	42HP	1	Anodized	Conductive	No
24572-609	4U	63HP	1	Anodized	Conductive	No
24572-610	4U	84HP	1	Anodized	Conductive	No
24572-599	2U	28HP	1	Anodized	Conductive	No
24572-600	2U	42HP	1	Anodized	Conductive	No
24572-601	2U	63HP	1	Anodized	Conductive	No
24572-602	2U	84HP	1	Anodized	Conductive	No

Table 2/2

Catalog Number	Quick Ship
24572-603	No
24572-604	No
24572-605	No
24572-606	No
24572-607	No
24572-608	No
24572-609	No

Catalog Number	Quick Ship
24572-610	No
24572-599	No
24572-600	No
24572-601	No
24572-602	No

ADDITIONAL PRODUCT DETAILS

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE