


RatiopacPRO Style, Front and Rear Trim, Screwless Front

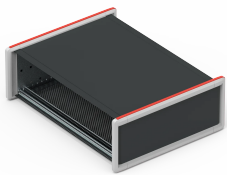

The versatile RatiopacPRO Style desktop case features a protective frame design, rubber strips, and various configuration options.

The Front and Rear Trims with Top & Bottom Rubber Strip option provides connector safeguarding and integrated stacking capability. The Circulated Rubber Strip design protects corner and is ideal for smaller mobile cases. For larger equipment, the Front Handle offers convenient carrying and rear connector protection.

Designed for 19" components with guide rails or proprietary components with a mounting plate, RatiopacPRO Style caters to your specific requirements.

FEATURES

Desktop case with protective frame design and rubber strips on the top and bottom for a secure stand and with integrated stacking function

Case for 19" components (guide rails) or proprietary components (mounting plate).

To establish EMC-shielding, additional components need to be added to the enclosure.

Front side for front panel mounting without screws and rear side prepared for standard front panel mounting.

Perforated bottom cover for air-cooling

No visible screws; cladding parts removable without tools

For board depth 160 mm, 220 mm, 280 mm and 340 mm (depending on case depth)

SPECIFICATIONS

Product Type:	Case
Type:	Case for Individual Electronic Components
Product Family:	RatiopacPRO Style

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Frame Construction	Cooling Option	Complies With
----------------	-------------	------------	------------------	--------------------------	----------------	---------------

24582-626	6U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-634	6U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-635	6U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-636	6U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-644	6U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-645	6U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-646	6U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-647	6U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

24582-214	2U	28HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-215	2U	28HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-224	2U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-225	2U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-226	2U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-234	2U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-235	2U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-236	2U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

24582-244	2U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-245	2U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-246	2U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-247	2U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-314	3U	28HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-315	3U	28HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-324	3U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-325	3U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

24582-326	3U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-334	3U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-335	3U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-336	3U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-344	3U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-345	3U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-346	3U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-347	3U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

24582-424	4U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-425	4U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-426	4U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-434	4U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-435	4U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-436	4U	63HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-444	4U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-445	4U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

24582-446	4U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-447	4U	84HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-624	6U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11
24582-625	6U	42HP	1	Side Trim, Horizontal Rails	Yes	IEC 60297-3-101, IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10, IEEE 1101.11

Table 2/2

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
24582-626	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-634	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-635	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-636	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-644	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-645	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
24582-646	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-647	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-214	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-215	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-224	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-225	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-226	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-234	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-235	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-236	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-244	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-245	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-246	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-247	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-314	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
24582-315	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-324	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-325	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-326	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-334	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-335	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-336	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-344	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-345	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-346	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-347	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-424	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-425	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-426	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-434	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No

Catalog Number	EMC Shielding	Finish	Material	Protection Rating	Quick Ship
24582-435	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-436	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-444	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-445	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-446	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-447	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-624	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No
24582-625	No (Retrofittable)	Anodized, Passivated, Powder Coated	Aluminum	IP30	No

ADDITIONAL PRODUCT DETAILS

For custom configurations (colors, sizes, etc.), please visit our online configurator (<https://configurators.schroff.biz/ratiopacpro-style>).

Modification service for customer specific versions on request (special colours, sizes, cut-outs, etc.).

Assembly service from lotsize 1.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE