


Static Handle Plastic in Trapezoid Form, Grey

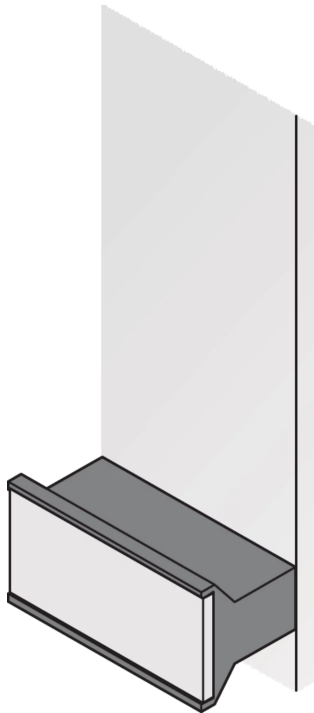

The static plastic handle, trapezoid form in grey color can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



FEATURES

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFICATIONS

Works With:	Front Panels
Product Type:	Handle
Material:	Polyphenylene Ether
Type:	Static

Table 1/2						
Catalog Number	Rack Width	Package Quantity	Handle Type	Flammability Rating	Color	Color Code
20808-062	8HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-004	10HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-067	28HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-009	40HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-068	42HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-012	61HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-003	5HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-060	6HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-061	7HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-063	9HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-064	12HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-065	14HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-066	21HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-294	3HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-295	4HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035


Table 2/2		
Catalog Number	Complies With	Quick Ship
20808-062	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No

Catalog Number	Complies With	Quick Ship
20808-004	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-067	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-009	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-068	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-012	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-003	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-060	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-061	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-063	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-064	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-065	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20808-066	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20809-294	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No
20809-295	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

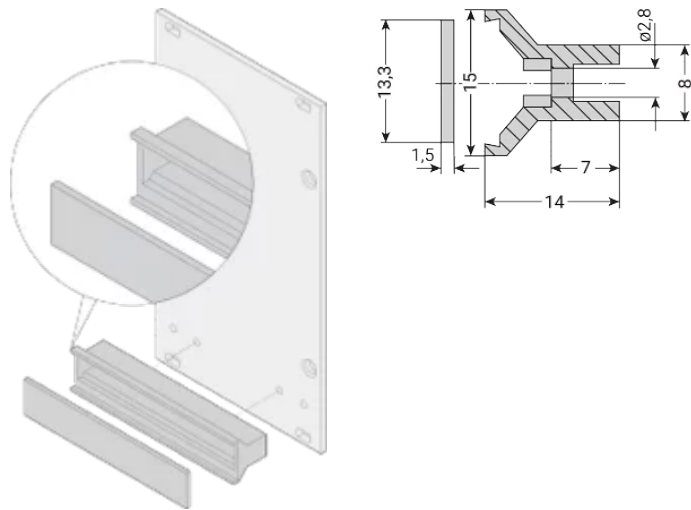

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE