


# Varistar CP Double Steel Door, Perforated, 3-Point Locking

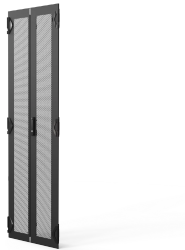

Perforated Varistar CP steel double door with 3-point locking for applications with IP 20 protection

## FEATURES

Double perforated steel door with 3 point locking for IP 20 protection class

Lever handle with key insert (2 keys)

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with lever handle 24630003 and DIN profile half cylinder with keys or push button

## SPECIFICATIONS

**Locking Type:** 3-Point Locking

**Product Type:** Cabinet Door

**Protection Rating:** IP20

**Material:** Steel

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Complies With	Finish
21630-448	24U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-449	24U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-450	29U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated

CatalogNumber	Rack Height	Package Quantity	Color	Color Code	Complies With	Finish
21630-451	29U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-452	33U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-453	33U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-454	38U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-455	38U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-020	42U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-027	42U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-021	47U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-028	47U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-022	52U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated
21630-029	52U	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-3	Powder Coated

Table 2/2			
Catalog Number	Type	Works With	Quick Ship
21630-448	Steel Double Door, Perforated	Varistar CP	No
21630-449	Steel Double Door, Perforated	Varistar CP	No
21630-450	Steel Double Door, Perforated	Varistar CP	No
21630-451	Steel Double Door, Perforated	Varistar CP	No
21630-452	Steel Double Door, Perforated	Varistar CP	No
21630-453	Steel Double Door, Perforated	Varistar CP	No

Catalog Number	Type	Works With	Quick Ship
21630-454	Steel Double Door, Perforated	Varistar CP	No
21630-455	Steel Double Door, Perforated	Varistar CP	No
21630-020	Steel Double Door, Perforated	Varistar CP	No
21630-027	Steel Double Door, Perforated	Varistar CP	No
21630-021	Steel Double Door, Perforated	Varistar CP	No
21630-028	Steel Double Door, Perforated	Varistar CP	No
21630-022	Steel Double Door, Perforated	Varistar CP	No
21630-029	Steel Double Door, Perforated	Varistar CP	No

## ADDITIONAL PRODUCT DETAILS

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**