


# Varistar CP Double Steel Door, Perforated With 3-Point Electronic Locking

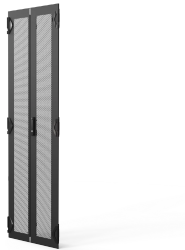

Perforated Varistar CP steel double door with 3-point locking and 2 door hinges for applications with IP 20 protection.

## FEATURES

Double perforated steel door with 3-point locking for IP 20 protection class

Lever handle with push button, key

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with DIN profile half cylinder

## SPECIFICATIONS

**Locking Type:** 3-Point Locking, Electronic

**Product Type:** Cabinet Door

**Protection Rating:** IP20

**Material:** Steel

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Complies With	Finish
21630-820	42U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated
21630-821	47U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated
21630-822	52U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated

CatalogNumber	Rack Height	Package Quantity	Color	Color Code	Complies With	Finish
21630-823	42U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated
21630-824	47U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated
21630-825	52U	1	Black Grey	RAL 7021	IEC 61587-1	Powder Coated

Table 2/2

Catalog Number	Type	Works With	Quick Ship
21630-820	Steel Double Door, Perforated	Varistar CP	No
21630-821	Steel Double Door, Perforated	Varistar CP	No
21630-822	Steel Double Door, Perforated	Varistar CP	No
21630-823	Steel Double Door, Perforated	Varistar CP	No
21630-824	Steel Double Door, Perforated	Varistar CP	No
21630-825	Steel Double Door, Perforated	Varistar CP	No

## ADDITIONAL PRODUCT DETAILS

Please order DIN profile half cylinder for lever handle separately.

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**