


# Varistar CP Mobile Base/Plinth

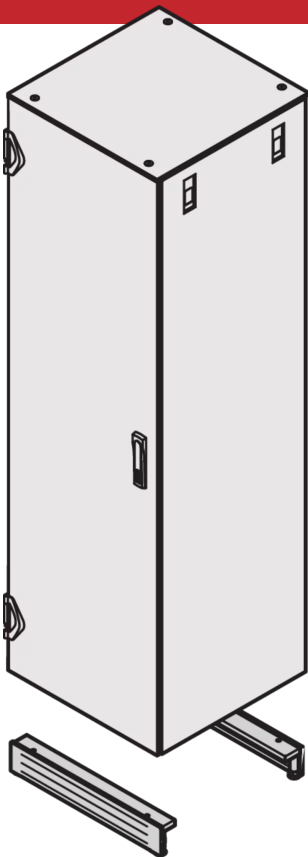

Mobile base/plinth to make a cabinet mobile.

## FEATURES

Covers, St, 1.5 mm

Load-carrying capacity on casters 400 kg, on adjustable feet 1600 kg

Support, St, 3 mm

Color RAL 7021

Plinth height H = 103 mm, with feet adjustable from 126 to 134 mm

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Base

**Material:** Steel

Table 1/2

Catalog Number	Package Quantity	Color	Color Code	Finish	Type	Works With
21630-655	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-656	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-657	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-658	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-661	1			Powder Coated	Base Plinth, Mobile	Varistar CP
21630-662	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-663	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP
21630-664	1	Black Grey	RAL 7021	Powder Coated	Base Plinth, Mobile	Varistar CP

Table 2/2

Catalog Number	Quick Ship
21630-655	No
21630-656	No
21630-657	No
21630-658	No
21630-661	No
21630-662	No
21630-663	No
21630-664	No

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**