


# Varistar CP Seismic Base Plate, Multi-Piece

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

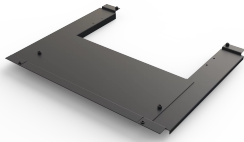

## FEATURES

To cover the base opening

The multi-piece base plate is open at the rear (opening to rear 200 mm deep, no rear opening with 300 mm cabinet depth)

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Base

**Material:** Steel

Table 1/2

Catalog Number	Package Quantity	Color	Color Code	Complies With	Finish	Type
20630-293	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-294	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-295	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-296	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-297	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-298	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain

CatalogNumber	Package Quantity	Color	Color Code	Complies With	Finish	Type
20630-299	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain
20630-300	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2	Powder Coated	Base Plate, Plain

Table 2/2

Catalog Number	Works With	Quick Ship
20630-293	Varistar CP	No
20630-294	Varistar CP	No
20630-295	Varistar CP	No
20630-296	Varistar CP	No
20630-297	Varistar CP	No
20630-298	Varistar CP	No
20630-299	Varistar CP	No
20630-300	Varistar CP	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**