


Varistar CP Top Cover Fan

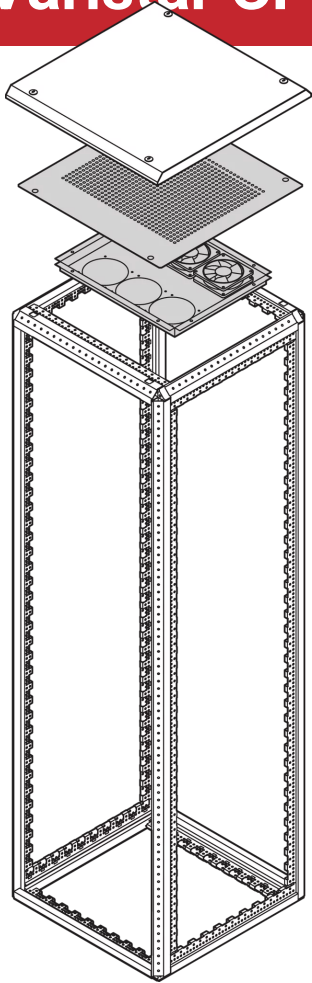

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

FEATURES

3 axial fans fitted (maximum: 6 fans)

C14 Socket

SPECIFICATIONS

Product Type: Fan
Material: Steel

Table 1/2

Catalog Number	Package Quantity	Color	Color Code	Finish	Protection Rating	Works With
21630-597	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-598	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-736	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-737	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-738	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-739	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-599	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-600	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-601	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-602	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-603	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-604	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-605	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-606	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-607	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-608	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-609	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-610	1	Black Grey	RAL 7021	Powder Coated		Varistar CP

CatalogNumber	Package Quantity	Color	Color Code	Finish	Protection Rating	Works With
21630-611	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-612	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-613	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-614	1	Black Grey	RAL 7021	Powder Coated		Varistar CP
21630-740	1	Black Grey	RAL 7021	Powder Coated	IP20	
21630-741	1	Black Grey	RAL 7021	Powder Coated	IP20	

Table 2/2

Catalog Number	Quick Ship
21630-597	No
21630-598	No
21630-736	No
21630-737	No
21630-738	No
21630-739	No
21630-599	No
21630-600	No
21630-601	No
21630-602	No
21630-603	No

Catalog Number	Quick Ship
21630-604	No
21630-605	No
21630-606	No
21630-607	No
21630-608	No
21630-609	No
21630-610	No
21630-611	No
21630-612	No
21630-613	No
21630-614	No
21630-740	No
21630-741	No

ADDITIONAL PRODUCT DETAILS

Please purchase the grounding kit, power cable, Thermostat or Speed controller separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE