

# nVent ERICO System 3000 Interceptor

## Data Solutions



### FEATURES

Dynamic response to the approach of a lightning downleader

Designed for lower height installations

Non-radioactive technology

No external power required

### SPECIFICATIONS

Table 1/2


| Catalog Number | Article Number | Material                        | Temperature  | Installation Height (H) | Diameter 1 (Ø1) | Diameter 2 (Ø2) |
|----------------|----------------|---------------------------------|--------------|-------------------------|-----------------|-----------------|
| INTMKIVSS      | 702089         | Stainless Steel 316 (EN 1.4401) | -40 to 100°C | 20m max                 | 101.6mm         | 26.15mm         |

Table 2/2

| Catalog Number | Article Number | Height (H) | Thread Size (TS) | Unit Weight |
|----------------|----------------|------------|------------------|-------------|
| INTMKIVSS      | 702089         | 348mm      | 1/2" BSPP        | 2.06kg      |

## DIAGRAMS

---

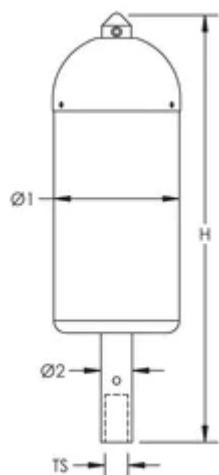

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**