

2 Hole Offset Lug



FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type LA connections only

SPECIFICATIONS

Material: Copper

Finish: Tinned

Table 1/2

Catalog Number	Type	Height (H)	Length (L)	Width (W)	Thickness (T)	A
B103AAOL003	Non-NEMA®	14.29 mm	95.25mm	12.7 mm	1.59 mm	15.9 mm
B102CEOL	NEMA®	15.88 mm	114.3mm	25.4 mm	3.18 mm	15.9 mm
B102CEOL001	NEMA®	15.88 mm	114.3mm	25.4 mm	3.18 mm	15.9 mm
B102QQOL	NEMA®	15.87 mm	114mm	25.4 mm	3.17 mm	15.8 mm
B103CEOL003	Non-NEMA®	15.88 mm	87.12mm	25.4 mm	3.18 mm	11.1 mm

CatalogNumber	Type	Height (H)	Length (L)	Width (W)	Thickness (T)	A
PBB102CEOL	NEMA®	16 mm	114.3mm	25.4 mm	3.18 mm	15.9 mm
B102DEOL	NEMA®	17.53 mm	114.3mm	25.4 mm	4.76 mm	15.9 mm
B103DEOL	Non-NEMA®	27.05 mm	114.3mm	25.4 mm	4.76 mm	15.9 mm
B102EEOL	NEMA®	19.05 mm	120.65mm	25.4 mm	6.35 mm	15.9 mm
B102EFOL	NEMA®	19.05 mm	120.65mm	31.75 mm	6.35 mm	15.9 mm
B102EGOL	NEMA®	19.05 mm	120.65mm	38.1 mm	6.35 mm	15.9 mm
B102EHOL	NEMA®	19.05 mm	127mm	50.8 mm	6.35 mm	15.9 mm
B103EEOL003	Non-NEMA®	19.05 mm	51.59mm	25.4 mm	6.35 mm	11.1 mm
B103EGOL001	Non-NEMA®	19.05 mm	92.08mm	38.1 mm	6.35 mm	11.1 mm
B102GGOL	NEMA®	31.75 mm	149.23mm	38.1 mm	9.53 mm	15.9 mm
B102GHOL	NEMA®	31.75 mm	149.23mm	50.8 mm	9.53 mm	15.9 mm
B102JHOL	NEMA®	34.93 mm	149.23mm	50.8 mm	12.7 mm	15.9 mm

Table 2/2


Catalog Number	B	C	D	Hole Size (HS)	Angle (a)	Equivalent Conductor Size
B103AAOL003	25.4 mm	57.15 mm	22.23 mm	6.35 mm	45 °	20.16mm ²
B102CEOL	44.45 mm	76.2 mm	22.23 mm	14.29 mm	45 °	80.63mm ²
B102CEOL001	44.45 mm	76.2 mm	22.23 mm	7.94 mm	45 °	80.63mm ²
B102QQOL	44.5 mm	76 mm	25.4 mm	14.2 mm	45 °	81mm ²
B103CEOL003	25.4 mm	49.02 mm	22.23 mm	11.11 mm	45 °	80.63mm ²

CatalogNumber	B	C	D	Hole Size (HS)	Angle (a)	Equivalent Conductor Size
PBB102CEOL	44.45 mm	76.2 mm	22.23 mm	14.29 mm	45 °	80.63mm ²
B102DEOL	44.45 mm	76.2 mm	22.23 mm	14.29 mm	45 °	120.94mm ²
B103DEOL	25.4 mm	49.02 mm	22.23 mm	11.11 mm	45 °	120.94mm ²
B102EEOL	44.45 mm	76.2 mm	26.92 mm	14.29 mm	45 °	161.26mm ²
B102EFOL	44.45 mm	76.2 mm	26.92 mm	14.29 mm	45 °	201.57mm ²
B102EGOL	44.45 mm	76.2 mm	26.92 mm	14.29 mm	45 °	242mm ²
B102EHOL	44.45 mm	76.2 mm	31.75 mm	14.29 mm	45 °	322.51mm ²
B103EEOL003	25.4 mm	51.59 mm	26.92 mm	11.11 mm	45 °	161.26mm ²
B103EGOL001	25.4 mm	50.8 mm	25.4 mm	11.11 mm	45 °	241.89mm ²
B102GGOL	44.45 mm	82.55 mm	38.1 mm	14.29 mm	45 °	362.83mm ²
B102GHOL	44.45 mm	82.55 mm	38.1 mm	14.29 mm	45 °	483.77mm ²
B102JHOL	44.45 mm	82.55 mm	50.8 mm	14.29 mm	45 °	645.03mm ²

ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

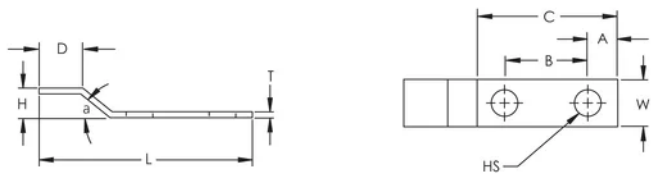

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE