

Single Hole Cable Strap



CERTIFICATIONS



FEATURES

Secures lightning protection conductors and prevents displacement

Mechanically secured with screws or nails

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Outer Diameter (OD)	Depth (D)	Width (W)	Hole Size (HS)
LPA803	Aluminum		11.91 mm	12.7mm	25 mm	4.76 mm
LPC801	Copper		11.91 mm	9.84mm	25 mm	4.76 mm
LPC801L	Copper	Tinned	11.91 mm	9.84mm	25 mm	4.76 mm
LPC803	Copper		11.91 mm	12.7mm	25 mm	4.76 mm

CatalogNumber	Material	Finish	Outer Diameter (OD)	Depth (D)	Width (W)	Hole Size (HS)
LPC803L	Copper	Tinned	11.91 mm	12.7mm	25 mm	4.76 mm
LPA807	Aluminum		33 mm	31.75mm	76.71 mm	7.14 mm
LPC807	Copper		33 mm	31.75mm	76.71 mm	7.14 mm
LPC807L	Copper	Tinned	33 mm	31.75mm	76.71 mm	7.14 mm
LPA805	Aluminum		12.7 mm	15.88mm	31.75 mm	7.14 mm
LPC805	Copper		12.7 mm	15.88mm	31.75 mm	7.14 mm
LPC805L	Copper	Tinned	12.7 mm	15.88mm	31.75 mm	7.14 mm
LPC80538	Copper		12.7 mm	15.88mm	31.75 mm	9.53 mm

Table 2/2


Catalog Number	Certifications
LPA803	
LPC801	E202878-Combined_CoC, E202878-Combined_CoC
LPC801L	E202878-Combined_CoC, E202878-Combined_CoC
LPC803	E202878-Combined_CoC, E202878-Combined_CoC
LPC803L	E202878-Combined_CoC, E202878-Combined_CoC
LPA807	
LPC807	E202878-Combined_CoC, E202878-Combined_CoC
LPC807L	E202878-Combined_CoC, E202878-Combined_CoC
LPA805	

Catalog Number	Certifications
LPC805	E202878-Combined_CoC, E202878-Combined_CoC
LPC805L	E202878-Combined_CoC, E202878-Combined_CoC
LPC80538	E202878-Combined_CoC, E202878-Combined_CoC

ADDITIONAL PRODUCT DETAILS

Typically installed every 3' (0.9 m) of conductor.

DIAGRAMS

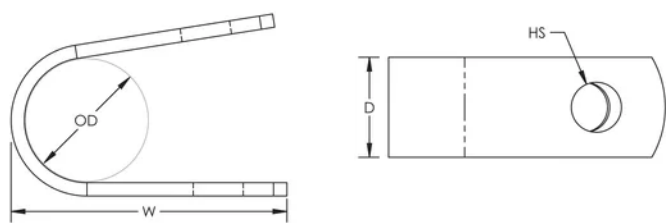

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE