

Tape Conductor



FEATURES

Lower impedance than equivalent sized round conductor

Used for lightning protection system downconductor or grounding applications

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Width (W)	Thickness (T)	Length (L)
A811A26F500		Copper	Bare	50.8 mm	0.4 mm	152.4m
A811A26F50		Copper	Bare	50.8 mm	0.4 mm	15.2m
A811A26W4F500		Copper	Bare	101.6 mm	0.4 mm	152.4m
TCEC30230	197650	Copper	Bare	30 mm	2 mm	30m
A811C20F100		Copper	Bare	76.2 mm	0.8 mm	30.5m
A811C20F20		Copper	Bare	76.2 mm	0.8 mm	6.1m
TCHGSP3530		Steel	Hot-Dip Galvanized	35 mm	3 mm	30m

CatalogNumber	Article Number	Material	Finish	Width (W)	Thickness (T)	Length (L)
TCHSSP3530		Stainless Steel 304 (EN 1.4301)	Bare	35 mm	3 mm	30m

Table 2/2


Catalog Number	Article Number	Unit Weight
A811A26F500		0.23 kg
A811A26F50		0.23 kg
A811A26W4F500		0.34 kg
TCEC30230	197650	0.53 kg
A811C20F100		0.61 kg
A811C20F20		0.61 kg
TCHGSP3530		0.82 kg
TCHSSP3530		1.6 kg

ADDITIONAL PRODUCT DETAILS

Cut-to-order (CTO) lengths are available for an additional charge.

Unit weight is per meter (3.28').

DIAGRAMS

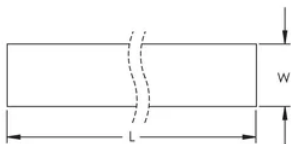

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE