

UFS nVent ERIFLEX Flexibar and IBSB Support Kit



CERTIFICATIONS



FEATURES

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Conductor Thickness	Conductor Width	Height (H)	Length (L)
UFS-KIT	553590	Aluminum, Polyamide	2 - 8 mm	15.5 - 120 mm	57.5 mm	2000mm

Table 2/2


Catalog Number	Article Number	Width (W)	A	B	Unit Weight
----------------	----------------	-----------	---	---	-------------

UFS-KIT	553590	30 mm	24 mm	15 mm	2.3 kg
---------	--------	-------	-------	-------	--------

ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

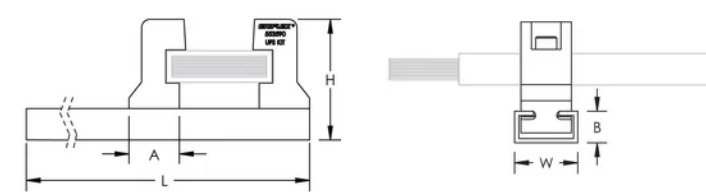

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE