

# Cable Tray to Rod Clip



## CERTIFICATIONS



## FEATURES

Supports cable tray up to 100 mm wide

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

## SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material     | Finish             | Rod Size (RS)        | Wire Size    | Flange Thickness (FT) |
|----------------|----------------|--------------|--------------------|----------------------|--------------|-----------------------|
| 4Z34CTS        | 172950         | Spring Steel | nVent CADDY Armour | M4, M6, M8, M10, M12 | 3.9 - 4.8 mm | 3.0 - 9.5 mm          |

Table 2/2

| Catalog Number | Article Number | A     | X           | Static Load |
|----------------|----------------|-------|-------------|-------------|
| 4Z34CTS        | 172950         | 68 mm | 35 x 6.5 mm | 90N         |


## ADDITIONAL PRODUCT DETAILS

---

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

## DIAGRAMS

---

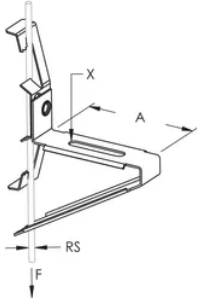

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

