

Hammer-On Flange Clip, Bottom Mount



CERTIFICATIONS



FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)
EM24S1	179720	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	6	200N
M24		Spring Steel	nVent CADDY Armour	3 - 8 mm	6	440N
M912		Spring Steel	nVent CADDY Armour	14 - 20 mm	6	440N
M58		Spring Steel	nVent CADDY Armour	8 - 14 mm	6	440N

CatalogNumber	Article Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)
EM58S1	179730	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	6	200N
EM912S1	179740	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	6	200N

Table 2/2

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM24S1	179720	110N	200N	
M24		330N	110N	cUL, UL
M912		330N	110N	cUL, UL
M58		330N	110N	cUL, UL
EM58S1	179730	110N	200N	
EM912S1	179740	110N	200N	

DIAGRAMS

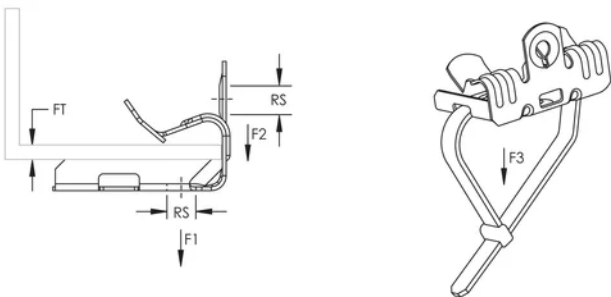

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

