

# 19" Front Panel

## Data Solutions

Front panels made of Aluminum.



### CERTIFICATIONS



### FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

### SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 95HP        |
| <b>Material:</b>       | Aluminum    |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/3

| Catalog Number | Rack Height | Depth (D) | Mounting       | Finish   | Front Finish | Package Quantity |
|----------------|-------------|-----------|----------------|----------|--------------|------------------|
| 30219-098      | 1U          | 3mm       | Screw-on Front | Anodized | Anodized     | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish        | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|---------------|--------------|------------------|
| 30118-948     | 1U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-299     | 1U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-074     | 1U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-101     | 2U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-301     | 2U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-949     | 2U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-075     | 2U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-104     | 3U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-302     | 3U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-950     | 3U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-076     | 3U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-107     | 4U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30118-303     | 4U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-951     | 4U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30219-110     | 5U          | 3mm       | Screw-on Front | Powder Coated | Anodized     | 1                |
| 30118-304     | 5U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-952     | 5U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-077     | 4U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish        | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|---------------|--------------|------------------|
| 30118-305     | 6U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-308     | 9U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-307     | 8U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-306     | 7U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-957     | 10U         | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-956     | 9U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-955     | 8U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-954     | 7U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-953     | 6U          | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 30118-309     | 10U         | 3mm       | Screw-on Front | Powder Coated | Painted      | 1                |
| 40304-078     | 5U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-143     | 9U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-144     | 10U         | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-138     | 8U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-079     | 6U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 30219-137     | 7U          | 3mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-080     | 7U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |
| 40304-081     | 8U          | 4mm       | Screw-on Front | Anodized      | Anodized     | 1                |

| CatalogNumber | Rack Height | Depth (D) | Mounting       | Finish   | Front Finish | Package Quantity |
|---------------|-------------|-----------|----------------|----------|--------------|------------------|
| 40304-082     | 9U          | 4mm       | Screw-on Front | Anodized | Anodized     | 1                |
| 40304-083     | 10U         | 4mm       | Screw-on Front | Anodized | Anodized     | 1                |
| 30219-113     | 6U          | 3mm       | Screw-on Front | Anodized | Anodized     | 1                |

| Table 2/3      |             |               |            |               |            |                 |
|----------------|-------------|---------------|------------|---------------|------------|-----------------|
| Catalog Number | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
| 30219-098      | Anodized    | No            |            | No            | 43.6mm     | 19" Front Panel |
| 30118-948      | Painted     |               | RAL 7021   | No            | 43.6mm     | 19" Front Panel |
| 30118-299      | Painted     |               | RAL 7035   | No            | 43.6mm     | 19" Front Panel |
| 40304-074      | Anodized    | Yes           |            | No            | 43.6mm     | 19" Front Panel |
| 30219-101      | Anodized    | No            |            | No            | 88.1mm     | 19" Front Panel |
| 30118-301      | Painted     |               | RAL 7035   | No            | 88.1mm     | 19" Front Panel |
| 30118-949      | Painted     |               | RAL 7021   | No            | 88.1mm     | 19" Front Panel |
| 40304-075      | Anodized    | Yes           |            | No            | 88.1mm     | 19" Front Panel |
| 30219-104      | Anodized    | No            |            | No            | 132.5mm    | 19" Front Panel |
| 30118-302      | Painted     |               | RAL 7035   | No            | 132.5mm    | 19" Front Panel |
| 30118-950      | Painted     |               | RAL 7021   | No            | 132.5mm    | 19" Front Panel |
| 40304-076      | Anodized    | Yes           |            | No            | 132.5mm    | 19" Front Panel |
| 30219-107      | Anodized    | No            |            | No            | 177mm      | 19" Front Panel |

| CatalogNumber | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|---------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30118-303     | Painted     |               | RAL 7035   | No            | 177mm      | 19" Front Panel |
| 30118-951     | Painted     |               | RAL 7021   | No            | 177mm      | 19" Front Panel |
| 30219-110     | Anodized    | No            |            | No            | 221.4mm    | 19" Front Panel |
| 30118-304     | Painted     |               | RAL 7035   | No            | 221.4mm    | 19" Front Panel |
| 30118-952     | Painted     |               | RAL 7021   | No            | 221.4mm    | 19" Front Panel |
| 40304-077     | Anodized    | Yes           |            | No            | 177mm      | 19" Front Panel |
| 30118-305     | Painted     |               | RAL 7035   | No            | 265.9mm    | 19" Front Panel |
| 30118-308     | Painted     |               | RAL 7035   | No            | 399.2mm    | 19" Front Panel |
| 30118-307     | Painted     |               | RAL 7035   | No            | 354.8mm    | 19" Front Panel |
| 30118-306     | Painted     |               | RAL 7035   | No            | 310.3mm    | 19" Front Panel |
| 30118-957     | Painted     |               | RAL 7021   | No            | 443.7mm    | 19" Front Panel |
| 30118-956     | Painted     |               | RAL 7021   | No            | 399.2mm    | 19" Front Panel |
| 30118-955     | Painted     |               | RAL 7021   | No            | 354.8mm    | 19" Front Panel |
| 30118-954     | Painted     |               | RAL 7021   | No            | 310.3mm    | 19" Front Panel |
| 30118-953     | Painted     |               | RAL 7021   | No            | 265.9mm    | 19" Front Panel |
| 30118-309     | Painted     |               | RAL 7035   | No            | 443.7mm    | 19" Front Panel |
| 40304-078     | Anodized    | Yes           |            | No            | 221.4mm    | 19" Front Panel |
| 30219-143     | Anodized    | No            |            | No            | 399.2mm    | 19" Front Panel |

| CatalogNumber | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|---------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30219-144     | Anodized    | No            |            | No            | 443.7mm    | 19" Front Panel |
| 30219-138     | Anodized    | No            |            | No            | 354.8mm    | 19" Front Panel |
| 40304-079     | Anodized    | Yes           |            | No            | 265.9mm    | 19" Front Panel |
| 30219-137     | Anodized    | No            |            | No            | 310.3mm    | 19" Front Panel |
| 40304-080     | Anodized    | Yes           |            | No            | 310.3mm    | 19" Front Panel |
| 40304-081     | Anodized    | Yes           |            | No            | 354.8mm    | 19" Front Panel |
| 40304-082     | Anodized    | Yes           |            | No            | 399.2mm    | 19" Front Panel |
| 40304-083     | Anodized    | Yes           |            | No            | 443.7mm    | 19" Front Panel |
| 30219-113     | Anodized    | No            |            | No            | 265.9mm    | 19" Front Panel |

Table 3/3

| Catalog Number | Width (W) |
|----------------|-----------|
| 30219-098      | 483mm     |
| 30118-948      | 483mm     |
| 30118-299      | 483mm     |
| 40304-074      | 483mm     |
| 30219-101      | 483mm     |
| 30118-301      | 483mm     |
| 30118-949      | 483mm     |
| 40304-075      | 483mm     |

| Catalog Number | Width (W) |
|----------------|-----------|
| 30219-104      | 483mm     |
| 30118-302      | 483mm     |
| 30118-950      | 483mm     |
| 40304-076      | 483mm     |
| 30219-107      | 483mm     |
| 30118-303      | 483mm     |
| 30118-951      | 483mm     |
| 30219-110      | 483mm     |
| 30118-304      | 483mm     |
| 30118-952      | 483mm     |
| 40304-077      | 483mm     |
| 30118-305      | 483mm     |
| 30118-308      | 483mm     |
| 30118-307      | 483mm     |
| 30118-306      | 483mm     |
| 30118-957      | 483mm     |
| 30118-956      | 483mm     |
| 30118-955      | 483mm     |

| Catalog Number | Width (W) |
|----------------|-----------|
| 30118-954      | 483mm     |
| 30118-953      | 483mm     |
| 30118-309      | 483mm     |
| 40304-078      | 483mm     |
| 30219-143      | 483mm     |
| 30219-144      | 483mm     |
| 30219-138      | 483mm     |
| 40304-079      | 483mm     |
| 30219-137      | 483mm     |
| 40304-080      | 483mm     |
| 40304-081      | 483mm     |
| 40304-082      | 483mm     |
| 40304-083      | 483mm     |
| 30219-113      | 483mm     |


## ADDITIONAL PRODUCT DETAILS

---

Please order 19" assembly kit separately.



DIAGRAMS

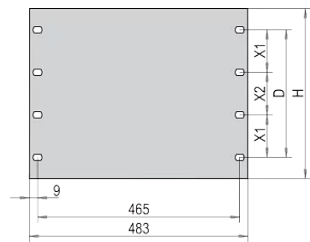

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE